

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0190700151](#)
Status: **Active**
Overview: [Solderless Terminals](#)
Description: InsulKrimp Ring Tongue Terminal for 10-12 AWG Wire, Stud Size 1/4" (M6), Length 34.21mm, Mylar Tape Carrier

Documents:

3D Model	Product Specification PS-19902-011-001 (PDF)
Drawing (PDF)	Product Specification PS-19902-015-001 (PDF)
3D Model (PDF)	RoHS Certificate of Compliance (PDF)
Product Specification PS-19902-009-001 (PDF)	

Agency Certification

CSA	LR18689
UL	E32244

General

Product Family	Ring and Spade Terminals
Series	19070
Crimp Quality Equipment	Yes
Overview	Solderless Terminals
Product Name	InsulKrimp
Type	Ring
UPC	800753069923

Physical

Barrel Type	Closed
Color - Resin	Natural
Flammability	94V-0
Insulation	PVC
Material - Plating Mating	Tin
Net Weight	2.745/g
Packaging Type	Adhesive Tape on Reel
Plating min - Mating	2.540µm
Plating min - Termination	2.540µm
Stud Size	1/4" (M6)
Wire Insulation Diameter	6.40mm max.
Wire Size AWG	10, 12

Solder Process Data


Lead-freeProcess Capability	N/A
-----------------------------	-----

Material Info

Engineering Number	C-240-14XT
--------------------	------------

Reference - Drawing Numbers

Product Specification	PS-19902-009-001, PS-19902-011-001, PS-19902-015-001
Sales Drawing	SD-19070-007

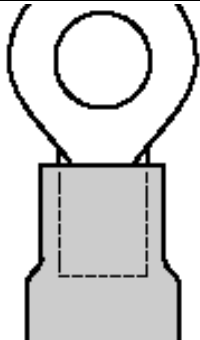

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

For more information, please visit [Contact US](#)

China RoHS

China ROHS	Not Reviewed
ELV	Not Relevant
RoHS Phthalates	Not Reviewed

Search Parts in this Series

[19070 Series](#)

Application Tooling | [FAQ](#)

Tooling specifications and manuals are found by selecting the products below. Crimp Height Specifications are then contained in the Application Tooling Specification document.

Global

Description	Product #
Perishable Tooling Spacers for tape product	190270133
ATP Crimp Dies for the Tape Crimp Module and ATP-101 & 301 Press	192880179
Mini-Mac Pneumatic Applicator for Industrial Terminals 6-26 AWG	638851500

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[19070-0151](#)