

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0190750008

Status:

Active

Overview:


Solderless Terminals

Description:

InsulKrimp Steel Star Ring Tongue Terminal for 18-22 AWG Wire, Stud Size 6 (M3.5), Mylar Tape Carrier

Documents:	
Drawing (PDF)	Product Specification PS-19902-011-001 (PDF)
Product Specification PS-19902-009-001 (PDF)	RoHS Certificate of Compliance (PDF)

Agency Certification	
CSA	LR18689
UL	E32244
General	
Product Family	Ring and Spade Terminals
Series	19075
Crimp Quality Equipment	Yes
Overview	Solderless Terminals
Product Name	InsulKrimp
Type	Ring
UPC	800753079502
Physical	
Barrel Type	Closed
Flammability	94V-0
Insulation	PVC
Material - Plating Mating	Tin
Net Weight	0.611/g
Packaging Type	Adhesive Tape on Reel
Stud Size	6 (M3.5)
Wire Insulation Diameter	3.68mm
Wire Size AWG	18, 20, 22
Material Info	
Engineering Number	SRA-S-229-06XT
Reference - Drawing Numbers	
Product Specification	PS-19902-009-001, PS-19902-011-001

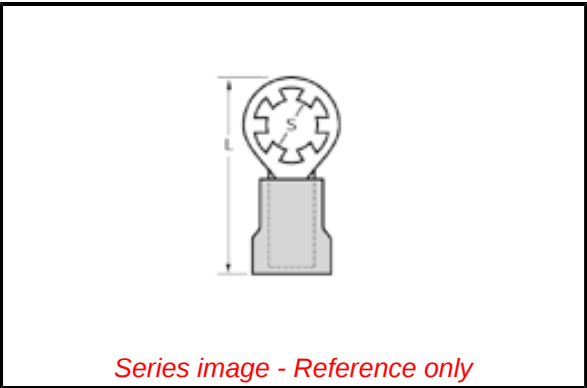

Series image - Reference only

EU ELV	
Not Relevant	
EU RoHS	China RoHS
Compliant	
REACH SVHC	
Contained Per -	
D(2021)4569-DC (8	
July 2021)	
reaction mass of	
2-ethylhexyl 10-	
ethyl-4,4-dioct	
Methylhexahydrophthalic	
anhydride	
Nonadecafluorodecanoic	
acid (PFDA) and its	
sodiu	
Aluminosilicate	
Refractory Ceramic	
Fibres	
Boric acid	
diisohexyl phthalate	
Terphenyl,	
hydrogenated	
2-(2H-Benzotriazol-2-	
yl)-4-(tert-butyl)-6-	
(sec-b	
2-(2H-Benzotriazol-2-	
yl)-4,6-	
ditertpentylphenol	
Dibutylbis(pentane-2,4-	
dionato-O,O')tin	
Disodium-octaborate	
Dibutyltin-dichloride	
1,2-	
Benzenedicarboxylic	
acid, bis(3-	
methylbutyl)	
Disodium 3,3'-[[1,1'-	
Biphenyl]-4,4'-	
Diylbis(Azo)	
Octanoic acid,	
2,2,3,3,4,4,5,5,6,6,7,7,8,8,8-	
pen	
Benzo(ghi)perylene	

Dipentyl phthalate
Imidazolidine-2-thione
Phenanthrene
Dihexyl-phthalate
4-aminoazobenzene
Silicic acid (H2Si2O5),
barium salt (1:1),
lead-
Cyanamide, lead(2+)
salt (1:1)
Lead titanium
zirconium oxide
Dioxobis(stearato)trilead
Tetralead-trioxide-
sulphate
Pentalead-tetraoxide-
sulphate
pyrochlore, antimony
lead yellow
Cadmium
Lead
Cadmium-sulphide
Cadmium-oxide
Diboron-trioxide
1,2-Dimethoxyethane
1,2-
Benzenedicarboxylic
acid, bis(2-
methoxyethyl
Pentazinc-chromate-
octahydroxide
Potassium
hydroxyoctaoxodizincatedichromate
bis(2-methoxyethyl)
ether
Boric acid, disodium
salt, hydrate
Tris(2-chloroethyl)
phosphate
Lead chromate
molybdate sulfate red
Lead chromate

**Halogen-Free
Status**

Not Low-Halogen

For more information, please visit [Contact US](#)

China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series
[19075 Series](#)

Application Tooling | [FAQ](#)
Tooling specifications and manuals are found by selecting the products below. Crimp Height Specifications are then contained in the Application Tooling Specification document.

Global	
Description	Product #

ATP Crimp Dies	<u>192880038</u>
for the Tape Crimp	
Module and ATP-101	
& 301 Press	
Mini-Mac Applicator	<u>638851400</u>

This document was generated on 10/04/2021

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[19075-0008](#)