


PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0190750010](#)
Status: **Active**
Overview: [Solderless Terminals](#)
Description: InsulKrimp Steel Star Ring Tongue Terminal for 18-22 AWG Wire, Stud Size 8 (M4), Mylar Tape Carrier

Documents:	
3D Model	Product Specification PS-19902-009-001 (PDF)
Drawing (PDF)	Product Specification PS-19902-011-001 (PDF)
3D Model (PDF)	RoHS Certificate of Compliance (PDF)

Agency Certification	
CSA	LR18689
UL	E32244
General	
Product Family	Ring and Spade Terminals
Series	19075
Crimp Quality Equipment	Yes
Overview	Solderless Terminals
Product Name	InsulKrimp
Type	Ring
UPC	800753079540
Physical	
Barrel Type	Closed
Flammability	94V-0
Insulation	PVC
Material - Plating Mating	Tin
Net Weight	0.566/g
Packaging Type	Adhesive Tape on Reel
Stud Size	8 (M4)
Wire Insulation Diameter	3.68mm
Wire Size AWG	18, 20, 22
Solder Process Data	
Lead-freeProcess Capability	N/A
Material Info	
Engineering Number	SRA-S-229-08XT
Reference - Drawing Numbers	
Product Specification	PS-19902-009-001, PS-19902-011-001

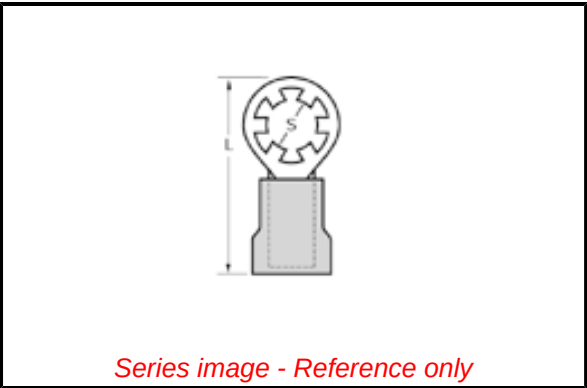

Series image - Reference only

EU ELV Not Relevant	
EU RoHS Compliant REACH SVHC Not Contained Per - D(2021)4569-DC (8 July 2021) Halogen-Free Status Not Low-Halogen	China RoHS
For more information, please visit Contact US	
China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series 19075 Series	
Application Tooling FAQ <i>Tooling specifications and manuals are found by selecting the products below. Crimp Height Specifications are then contained in the Application Tooling Specification document.</i>	
Global	
Description	Product #
ATP Crimp Dies for the Tape Crimp Module and ATP-101 & 301 Press	192880038
Mini-Mac Applicator	638851400

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[19075-0010](#)