


PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0190770017](#)
Status: **Active**
Overview: [Solderless Terminals](#)
Description: Avikrimp Star Ring Tongue Terminal 14-16 AWG Wire, Stud Size 8 (M4)

Documents:
[3D Model](#) [Product Specification PS-19902-011-001 \(PDF\)](#)
[3D Model \(PDF\)](#) [Product Specification PS-19902-013-001 \(PDF\)](#)
[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification	
CSA	LR18689
UL	E32244
General	
Product Family	Ring and Spade Terminals
Series	19077
Crimp Quality Equipment	Yes
Overview	Solderless Terminals
Product Name	Avikrimp
Type	Ring
UPC	800753080928
Physical	
Barrel Type	Closed
Flammability	94V-2
Insulation	Nylon (PA)
Material - Plating Mating	Tin
Net Weight	0.936/g
Packaging Type	Bag
Plating min - Mating	2.540µm
Plating min - Termination	2.540µm
Stud Size	8 (M4)
Termination Interface: Style	Crimp or Compression
Wire Insulation Diameter	4.29mm max.
Wire Size AWG	14, 16
Material Info	
Engineering Number	SRB-829-08

Reference - Drawing Numbers
[Product Specification](#) PS-19902-011-001, PS-19902-013-001
[Sales Drawing](#) SD-19077-001-001

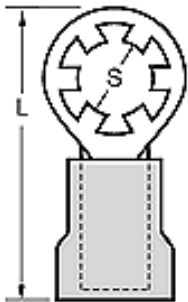

Series image - Reference only

EU ELV
Not Relevant

EU RoHS Compliant REACH SVHC Not Contained Per - D(2021)4569-DC (8 July 2021) Halogen-Free Status Low-Halogen For more information, please visit Contact US	China RoHS China ROHS ELV RoHS Phthalates
	Green Image Not Relevant Not Contained

Search Parts in this Series
[19077 Series](#)

Application Tooling | [FAQ](#)
Tooling specifications and manuals are found by selecting the products below. Crimp Height Specifications are then contained in the Application Tooling Specification document.

Global	
Description	Product #
Hand Crimp Tool	640011900
Crimp Head for the AT-200 Pneumatic Hand Tool	640051900

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[19077-0017](#)