


PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: 0190840008
Status: Active
Overview: Solderless Terminals
Description: Open Barrel Star Ring , Tin-Plated Steel, for 14-18 AWG Wire Range, Stud Size 8 (M4)

Documents:
[3D Model](#) [Product Specification PS-19902-006-001 \(PDF\)](#)
[3D Model \(PDF\)](#) [Product Specification PS-19902-011-001 \(PDF\)](#)
[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification	
CSA	LR18689
UL	E32244
General	
Product Family	Ring and Spade Terminals
Series	19084
Crimp Quality Equipment	Yes
Overview	Solderless Terminals
Product Name	N/A
Type	Ring
UPC	800755080223
Physical	
Barrel Type	Open
Insulation	None
Material - Plating Mating	Tin
Net Weight	0.758/g
Packaging Type	Reel
Plating min - Mating	2.540µm
Plating min - Termination	2.540µm
Stud Size	8 (M4)
Termination Interface: Style	Crimp or Compression
Wire Insulation Diameter	N/A
Wire Size AWG	14, 16, 18
Wire Size mm²	0.80-2.00
Solder Process Data	
Lead-freeProcess Capability	N/A
Material Info	
Engineering Number	SRZ-S-4129-08
Reference - Drawing Numbers	
Product Specification	PS-19902-006-001, PS-19902-011-001
Sales Drawing	SD-19084-001-001

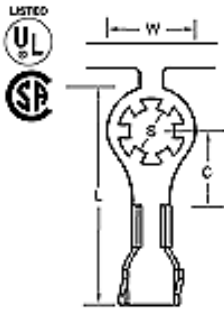

Series image - Reference only

EU ELV Not Relevant	
EU RoHS Compliant REACH SVHC Not Contained Per - D(2021)4569-DC (8 July 2021) Halogen-Free Status Low-Halogen For more information, please visit Contact US	China RoHS China ROHS ELV RoHS Phthalates
	Green Image Not Relevant Not Contained

Search Parts in this Series
19084 Series

Application Tooling | FAQ
Tooling specifications and manuals are found by selecting the products below. Crimp Height Specifications are then contained in the Application Tooling Specification document.
Global

Description	Product #
Mini-Mac Applicator	638815600

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[19084-0008](#)