

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0190840009](#)
Status: **Active**
Overview: [Solderless Terminals](#)
Description: Open Barrel Star Ring , Tin-Plated Steel, for 14-18 AWG Wire Range, Stud Size 10 (M5)

Documents:
[3D Model](#) [Product Specification PS-19902-006-001 \(PDF\)](#)
[Drawing \(PDF\)](#) [Product Specification PS-19902-011-001 \(PDF\)](#)
[3D Model \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification
CSA LR18689
UL E32244


General
Product Family Ring and Spade Terminals
Series [19084](#)
Crimp Quality Equipment Yes
Overview [Solderless Terminals](#)
Product Name N/A
Type Ring
UPC 800755080230

Physical
Barrel Type Open
Insulation None
Material - Plating Mating Tin
Net Weight 0.735/g
Packaging Type Reel
Plating min - Mating 2.540µm
Plating min - Termination 2.540µm
Stud Size 10 (M5)
Termination Interface: Style Crimp or Compression
Wire Insulation Diameter N/A
Wire Size AWG 14, 16, 18
Wire Size mm² 0.80-2.00

Solder Process Data
Lead-freeProcess Capability N/A

Material Info
Engineering Number SRZ-S-4129-10

Reference - Drawing Numbers
Product Specification PS-19902-006-001, PS-19902-011-001
Sales Drawing SD-19084-001-001

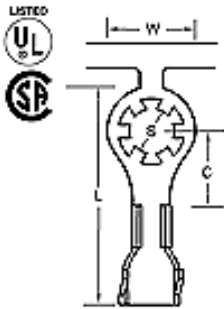

Series image - Reference only

EU ELV
Not Relevant

EU RoHS **China RoHS**
Compliant
REACH SVHC
Not Contained Per -
D(2021)4569-DC (8
July 2021)
Halogen-Free
Status
Low-Halogen
For more information, please visit [Contact US](#)

China ROHS Green Image
ELV Not Relevant
RoHS Phthalates Not Contained

Search Parts in this Series
[19084 Series](#)

Application Tooling | FAQ
Tooling specifications and manuals are found by selecting the products below. Crimp Height Specifications are then contained in the Application Tooling Specification document.
Global

Description	Product #
Mini-Mac Applicator	638815600

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Molex:

19084-0009