


PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0190850007](#)
Status: **Active**
Overview: [Solderless Terminals](#)
Description: Open Barrel Ring , Tin-Plated Steel, for 14-18 AWG Wire, Stud Size 6 (M3.5)

Documents:
[Drawing \(PDF\)](#) [Product Specification PS-19902-011-001 \(PDF\)](#)
[Product Specification PS-19902-006-001 \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

General	
Product Family	Ring and Spade Terminals
Series	19085
Crimp Quality Equipment	Yes
Overview	Solderless Terminals
Product Name	N/A
Type	Ring
UPC	800755080308
Physical	
Barrel Type	Open
Insulation	None
Material - Plating Mating	Tin
Net Weight	2.070/g
Packaging Type	Reel
Stud Size	6 (M3.5)
Temperature Range - Operating	149°C
Wire Insulation Diameter	N/A
Wire Size AWG	14, 16, 18
Wire Size mm²	0.80-2.00
Electrical	
Voltage - Maximum	2000V
Material Info	
Engineering Number	RZ-S-4129-06
Reference - Drawing Numbers	
Product Specification	PS-19902-006-001, PS-19902-011-001
Sales Drawing	SD-19085-002-001

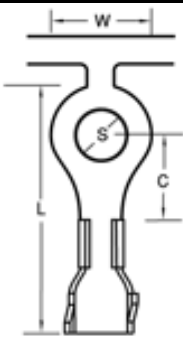

Series image - Reference only

EU ELV Not Relevant	
EU RoHS Not Relevant	China RoHS
REACH SVHC Not Contained Per - D(2021)4569-DC (8 July 2021)	
Halogen-Free Status Low-Halogen	
For more information, please visit Contact US	
China ROHS	Not Relevant
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series
[19085 Series](#)

Application Tooling | [FAQ](#)
Tooling specifications and manuals are found by selecting the products below. Crimp Height Specifications are then contained in the Application Tooling Specification document.
Global

Description	Product #
Mini-Mac Applicator	638815600

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[19085-0007](#)