

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: 0190850009
Status: Active
Overview: Solderless Terminals
Description: Open Barrel Ring , Tin-Plated Steel, for 14-18 AWG Wire, Stud Size 10 (M5)

Documents:	
3D Model	Product Specification PS-19902-006-001 (PDF)
Drawing (PDF)	Product Specification PS-19902-011-001 (PDF)
3D Model (PDF)	RoHS Certificate of Compliance (PDF)

Agency Certification

CSA	LR18689
UL	E32244

General

Product Family	Ring and Spade Terminals
Series	19085
Crimp Quality Equipment	Yes
Overview	Solderless Terminals
Product Name	N/A
Type	Ring
UPC	800755080322

Physical

Barrel Type	Open
Insulation	None
Material - Plating Mating	Tin
Net Weight	0.770/g
Packaging Type	Reel
Stud Size	10 (M5)
Temperature Range - Operating	149°C
Wire Insulation Diameter	N/A
Wire Size AWG	14, 16, 18
Wire Size mm²	0.80-2.00

Electrical


Voltage - Maximum	2000V
-------------------	-------

Material Info

Engineering Number	RZ-S-4129-10
--------------------	--------------

Reference - Drawing Numbers

Product Specification	PS-19902-006-001, PS-19902-011-001
Sales Drawing	SD-19085-002-001

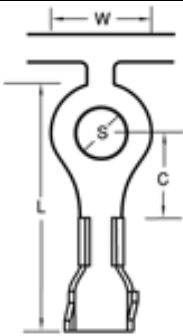

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

China RoHS

REACH SVHC

Not Contained Per -
D(2021)4569-DC (8
July 2021)

Halogen-Free

Status

Not Relevant

For more information, please visit [Contact US](#)

China ROHS	Not Relevant
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

19085 Series

Application Tooling | FAQ

Tooling specifications and manuals are found by selecting the products below. Crimp Height Specifications are then contained in the Application Tooling Specification document.

Global

Description	Product #
Mini-Mac Applicator	638815600

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[19085-0009](#)