

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0190980048](#)
Status: **Active**
Overview: [Solderless Terminals](#)
Description: Krimptite Snap Spade Tongue Terminal for 14-16 AWG Wire, Stud Size 8 (M4), Length 16.41mm, Mylar Tape Carrier

Documents:
[3D Model](#) [Product Specification PS-19902-011-001 \(PDF\)](#)
[Drawing \(PDF\)](#) [Product Specification PS-19902-015-001 \(PDF\)](#)
[3D Model \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)


Agency Certification
CSA LR18689
UL E32244

General
Product Family Ring and Spade Terminals
Series [19098](#)
Crimp Quality Equipment Yes
Overview [Solderless Terminals](#)
Product Name Krimptite
Type Spade Snap
UPC 800753088306

Physical
Barrel Type Closed
Insulation None
Material - Plating Mating Tin
Net Weight 0.646/g
Packaging Type Adhesive Tape on Reel
Stud Size 8 (M4)
Wire Size AWG 14, 16
Wire Size mm² 1.00-2.50

Material Info
Engineering Number BB-1716-08T

Reference - Drawing Numbers
Product Specification PS-19902-011-001, PS-19902-015-001
Sales Drawing SD-19098-004-001

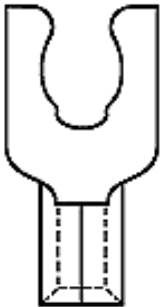

Series image - Reference only

EU ELV
Not Relevant

EU RoHS **China RoHS**
Compliant
REACH SVHC
Not Contained Per -
D(2021)4569-DC (8
July 2021)
Halogen-Free
Status
Low-Halogen
For more information, please visit [Contact US](#)

China ROHS Green Image
ELV Not Relevant
RoHS Phthalates Not Contained

Search Parts in this Series
[19098](#) Series

Application Tooling | FAQ
Tooling specifications and manuals are found by selecting the products below. Crimp Height Specifications are then contained in the Application Tooling Specification document.

Global	
Description	Product #
ATP Crimp Dies for the Tape Crimp Module and ATP-101 & 301 Press	190270068
Mini-Mac Applicator, Air Feed Mylar Tape	638853900

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Molex:

19098-0048