

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0190980070](#)
Status: **Active**
Overview: [Solderless Terminals](#)
Description: Krimptite Snap Spade Terminal, for 10-12 AWG Wire, Stud Size 5 (M3), 16.87mm Length


Documents:	
3D Model	Product Specification PS-19902-011-001 (PDF)
Drawing (PDF)	Product Specification PS-19902-015-001 (PDF)
3D Model (PDF)	RoHS Certificate of Compliance (PDF)

Agency Certification	
CSA	LR18689
UL	E32244
General	
Product Family	Ring and Spade Terminals
Series	19098
Crimp Quality Equipment	Yes
Overview	Solderless Terminals
Product Name	Krimptite
Type	Spade Snap
UPC	800753088481

Physical	
Barrel Type	Closed
Insulation	None
Material - Plating Mating	Tin
Net Weight	1.109/g
Packaging Type	Adhesive Tape on Reel
Stud Size	5 (M3)
Wire Size AWG	10, 12
Wire Size mm²	3.30-5.00

Solder Process Data	
Lead-freeProcess Capability	N/A
Material Info	
Engineering Number	C-1710-06T

Reference - Drawing Numbers	
Product Specification	PS-19902-011-001, PS-19902-015-001
Sales Drawing	CCD10502-001

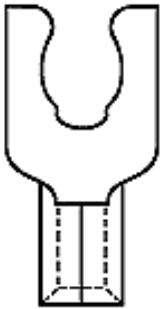

Series image - Reference only

EU ELV Not Relevant	
EU RoHS Compliant	China RoHS
REACH SVHC Not Contained Per - D(2021)4569-DC (8 July 2021)	
Halogen-Free Status Low-Halogen	
For more information, please visit Contact US	
China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series
[19098 Series](#)

Application Tooling FAQ	
<i>Tooling specifications and manuals are found by selecting the products below. Crimp Height Specifications are then contained in the Application Tooling Specification document.</i>	
Global	
Description	Product #
ATP Crimp Dies for the Tape Crimp Module and ATP-101 & 301 Press	190270088
Mini-Mac Applicator	638851000

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[19098-0070](#)