

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0190980091](#)
Status: **Active**
Overview: [Solderless Terminals](#)
Description: Krimptite Snap Spade Terminal, for 10-12 AWG Wire, Stud Size 10 (M5), 19.60mm Length

Documents:
[3D Model](#) [Product Specification PS-19902-011-001 \(PDF\)](#)
[Drawing \(PDF\)](#) [Product Specification PS-19902-015-001 \(PDF\)](#)
[3D Model \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)


Agency Certification
CSA LR18689
UL E32244

General
Product Family Ring and Spade Terminals
Series [19098](#)
Crimp Quality Equipment Yes
Overview [Solderless Terminals](#)
Product Name Krimptite
Type Spade Snap
UPC 800753088597

Physical
Barrel Type Closed
Insulation None
Material - Plating Mating Tin
Net Weight 1.213/g
Packaging Type Bag
Stud Size 10 (M5)
Temperature Range - Operating 149°C
Wire Size AWG 10, 12

Material Info
Engineering Number C-1718-08T

Reference - Drawing Numbers
Product Specification PS-19902-011-001, PS-19902-015-001
Sales Drawing CCD10503-001

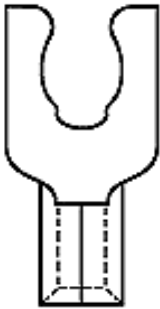

Series image - Reference only

EU ELV
Not Relevant

EU RoHS	China RoHS
Compliant	
REACH SVHC	
Not Contained Per - D(2021)4569-DC (8 July 2021)	
Halogen-Free	
Status	
Low-Halogen	
For more information, please visit Contact US	
China ROHS	Not Relevant
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series
[19098 Series](#)

Application Tooling | [FAQ](#)
Tooling specifications and manuals are found by selecting the products below. Crimp Height Specifications are then contained in the Application Tooling Specification document.

Global	
Description	Product #
ATP Crimp Dies for the Tape Crimp Module and ATP-101 & 301 Press	190270088
Mini-Mac Applicator	638851000

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[19098-0091](#)