

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0190990032

Status:

Active

Overview:

Solderless Terminals

Description:

InsulKrimp Snap Spade Terminal for 14-16 AWG Wire, Blue

Documents:

Drawing (PDF)

Product Specification PS-19902-009-001 (PDF)

Product Specification PS-19902-011-001 (PDF)

Product Specification PS-19902-013-001 (PDF)

RoHS Certificate of Compliance (PDF)

Agency Certification

CSA

LR18689

UL

E32244

General

Product Family

Ring and Spade Terminals

Series

19099

Crimp Quality Equipment

Yes

Overview

Solderless Terminals

Product Name

InsulKrimp

Type

Spade Snap

UPC

800753089181

Physical

Barrel Type

Closed

Color - Resin

Blue

Flammability

94V-0

Insulation

PVC

Material - Plating Mating

Tin

Net Weight

0.811/g

Packaging Type

Bag

Stud Size

8 (M4)

Wire Insulation Diameter

4.40mm max.

Wire Size AWG

14, 16

Wire Size mm²

1.30-2.00

Solder Process Data

Lead-freeProcess Capability

N/A

Material Info

Engineering Number

BB-2716-08X


Reference - Drawing Numbers

Product Specification

PS-19902-009-001, PS-19902-011-001, PS-19902-013-001

Sales Drawing

190990032-000

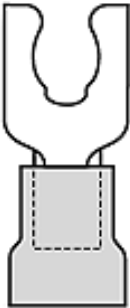

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

China RoHS

Compliant

REACH SVHC

Not Contained Per -

D(2021)4569-DC (8

July 2021)

Halogen-Free

Status

Not Low-Halogen

For more information, please visit

Contact US

China ROHS

Green Image

ELV

Not Relevant

RoHS Phthalates

Not Contained

Search Parts in this Series

19099 Series

Application Tooling | FAQ

Tooling specifications and manuals are found by selecting the products below. Crimp Height Specifications are then contained in the Application Tooling Specification document.

Global	
Description	Product #
PremiumGrade	640010100
Hand Crimp Tool for Avikrimp and Insulkrimp Terminals and Splices, 10-22 AWG and 6.0-0.5mm² (Rings, Spades, Hooks, Block Spades and Flanged Spades)	
PremiumGrade	640010300
Hand Crimp Tool for Insulkrimp Terminals and Splices, 10-22	

AWG (Rings,
Spades, Hooks,
Block Spades and
Flanged Spades)
Crimp Head for the 640050100
AT-200 Pneumatic
Hand Tool
Crimp Head for the 640050300
AT-200 Pneumatic
Hand Tool
ServiceGrade Hand 640160036
Crimp Tool for Field
Repair only, for
production use our
PremiumGrade Tool

This document was generated on 09/13/2021
PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[19099-0032](#)