

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0190990050

Status:


Active

Overview:

Solderless Terminals

Description:

InsulKrimp Snap Spade Terminal for 10-12 AWG Wire, Yellow

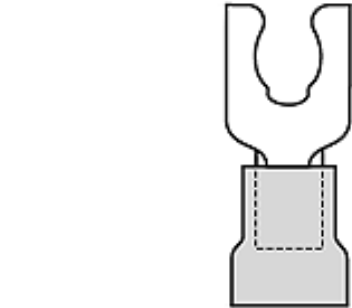

Series image - Reference only

Documents:

3D Model

Product Specification PS-19902-011-001 (PDF)

3D Model (PDF)

Product Specification PS-19902-013-001 (PDF)

Drawing (PDF)

RoHS Certificate of Compliance (PDF)

Product Specification PS-19902-009-001 (PDF)

Agency Certification	
CSA	LR18689
UL	E32244
General	
Product Family	Ring and Spade Terminals
Series	19099
Crimp Quality Equipment	Yes
Overview	Solderless Terminals
Product Name	InsulKrimp
Type	Spade Snap
UPC	800753089488
Physical	
Barrel Type	Closed
Color - Resin	Yellow
Flammability	94V-0
Insulation	PVC
Material - Plating Mating	Tin
Net Weight	1.645/g
Packaging Type	Bag
Stud Size	10 (M5)
Wire Insulation Diameter	6.40mm max.
Wire Size AWG	10, 12
Wire Size mm²	3.30-5.00
Solder Process Data	
Lead-freeProcess Capability	N/A
Material Info	
Engineering Number	C-2719-10X

Reference - Drawing Numbers

Product Specification

PS-19902-009-001, PS-19902-011-001, PS-19902-013-001

Sales Drawing

1339-02, 190990048-000

EU ELV

Not Relevant

EU RoHS

Compliant

China RoHS

REACH SVHC

Not Contained Per -
D(2021)4569-DC (8
July 2021)

Halogen-Free

Status

Not Low-Halogen

For more information, please visit [Contact US](#)

China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

19099 Series

Application Tooling | [FAQ](#)

Tooling specifications and manuals are found by selecting the products below. Crimp Height Specifications are then contained in the Application Tooling Specification document.

Global

Description	Product #
PremiumGrade Hand Crimp Tool for Avikrimp and Insulkrimp Terminals and Splices, 10-22 AWG and 6.0-0.5mm² (Rings, Spades, Hooks, Block Spades and Flanged Spades)	640010100
PremiumGrade Hand Crimp Tool for Insulkrimp Terminals and Splices, 10-22	640010300

AWG (Rings,
Spades, Hooks,
Block Spades and
Flanged Spades)
Crimp Head for the 640050100
AT-200 Pneumatic
Hand Tool
Crimp Head for the 640050300
AT-200 Pneumatic
Hand Tool
ServiceGrade Hand 640160036
Crimp Tool for Field
Repair only, for
production use our
PremiumGrade Tool

This document was generated on 09/14/2021
PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Molex:

19099-0050