

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: 0191150013
Status: Active
Overview: Solderless Terminals
Description: Avikrimp Snap Spade Terminal for 18-22 AWG Wire

Documents:
3D Model Product Specification PS-19902-011-001 (PDF)
Drawing (PDF) RoHS Certificate of Compliance (PDF)
3D Model (PDF)


Agency Certification
CSA LR18689
UL E32244

General
Product Family Ring and Spade Terminals
Series 19115
Crimp Quality Equipment Yes
Overview Solderless Terminals
Product Name Avikrimp
Type Spade Snap
UPC 800753091924

Physical
Barrel Type Closed
Flammability 94V-2
Insulation Nylon (PA)
Material - Plating Mating Tin
Net Weight 0.834/g
Packaging Type Adhesive Tape on Reel
Plating min - Mating 4.064µm
Plating min - Termination 4.064µm
Stud Size 8 (M4)
Wire Insulation Diameter 3.60mm max.
Wire Size AWG 18, 20, 22

Material Info
Engineering Number AA-8714-08T

Reference - Drawing Numbers
Product Specification PS-19902-011-001
Sales Drawing SD-19115-001-001

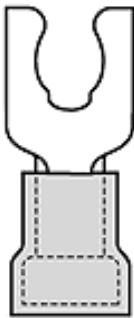

Series image - Reference only

EU ELV
Not Relevant

EU RoHS **China RoHS**
Compliant
REACH SVHC
Not Contained Per -
D(2021)4569-DC (8
July 2021)
Halogen-Free
Status
Low-Halogen

For more information, please visit [Contact US](#)

China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series
19115 Series

Application Tooling | FAQ
Tooling specifications and manuals are found by selecting the products below. Crimp Height Specifications are then contained in the Application Tooling Specification document.

Global	
Description	Product #
ATP Crimp Dies for the Tape Crimp Module and ATP-101 & 301 Press	192880023
FineAdjust Pneumatic Applicator for Ring and Spade Terminals, 18-22 AWG	638851300

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Molex:

[19115-0013](#) [19115-0038](#) [19115-0002](#) [19115-0004](#)