

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0191180081](#)
Status: **Active**
Overview: [Solderless Terminals](#)
Description: Krimptite Flanged Spade Tongue Terminal for 10-12 AWG Wire, Stud Size 8 (M4), Length 19.91mm, Mylar Tape Carrier

Documents:

3D Model	Product Specification PS-19902-011-001 (PDF)
Drawing (PDF)	Product Specification PS-19902-015-001 (PDF)
3D Model (PDF)	RoHS Certificate of Compliance (PDF)

Agency Certification

CSA	LR18689
UL	E32244

General

Product Family	Ring and Spade Terminals
Series	19118
Crimp Quality Equipment	Yes
Overview	Solderless Terminals
Product Name	Krimptite
Type	Spade
UPC	800753093805

Physical


Barrel Type	Closed
Insulation	None
Material - Plating Mating	Tin
Net Weight	1.447/g
Packaging Type	Adhesive Tape on Reel
Stud Size	8 (M4)
Wire Size AWG	10, 12
Wire Size mm²	4.00-6.00

Material Info

Engineering Number	C-1104-08T
--------------------	------------

Reference - Drawing Numbers

Product Specification	PS-19902-011-001, PS-19902-015-001
Sales Drawing	CCD10401-001

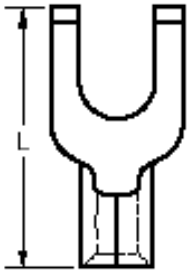

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

China RoHS

REACH SVHC

Not Contained Per -
D(2021)4569-DC (8
July 2021)

Halogen-Free

Status

Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

Green Image

ELV

Not Relevant

RoHS Phthalates

Not Contained

Search Parts in this Series

[19118 Series](#)

Application Tooling | [FAQ](#)

Tooling specifications and manuals are found by selecting the products below. Crimp Height Specifications are then contained in the Application Tooling Specification document.

Global

Description	Product #
ATP Crimp Dies for the Tape Crimp Module and ATP-101 & 301 Press	190270088
Mini-Mac Applicator	638851000

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[19118-0081](#)