

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0191180087](#)
Status: **Active**
Overview: [Solderless Terminals](#)
Description: Krimptite Flanged Spade Tongue Terminal for 10-12 AWG Wire, Stud Size 8 (M4), Length 19.56mm, Mylar Tape Carrier

Documents:

3D Model	Product Specification PS-19902-011-001 (PDF)
Drawing (PDF)	Product Specification PS-19902-015-001 (PDF)
3D Model (PDF)	RoHS Certificate of Compliance (PDF)

Agency Certification

CSA	LR18689
UL	E32244

General

Product Family	Ring and Spade Terminals
Series	19118
Crimp Quality Equipment	Yes
Overview	Solderless Terminals
Product Name	Krimptite
Type	Spade
UPC	800753093850

Physical


Barrel Type	Closed
Insulation	None
Material - Plating Mating	Tin
Net Weight	1.511/g
Packaging Type	Adhesive Tape on Reel
Plating min - Mating	4.064µm
Plating min - Termination	4.064µm
Stud Size	8 (M4)
Wire Size AWG	10, 12
Wire Size mm²	4.00-6.00

Material Info

Engineering Number	C-117-08T
--------------------	-----------

Reference - Drawing Numbers

Product Specification	PS-19902-011-001, PS-19902-015-001
Sales Drawing	SD-19118-002

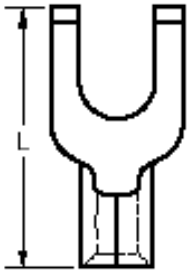

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

For more information, please visit [Contact US](#)

China RoHS

China ROHS	Not Reviewed
ELV	Not Relevant
RoHS Phthalates	Not Reviewed

Search Parts in this Series

[19118](#) Series

Application Tooling | [FAQ](#)

Tooling specifications and manuals are found by selecting the products below. Crimp Height Specifications are then contained in the Application Tooling Specification document.

Global

Description	Product #
ATP Crimp Dies for the Tape Crimp Module and ATP-101 & 301 Press	190270088
Mini-Mac Applicator	638851000

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[19118-0087](#)