

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0191310030

Status:


Active

Overview:

Solderless Terminals

Description:

InsulKrimp Block Spade Tongue Terminal for 18 to 22 AWG Wire, Stud Size 6 (M3.5), Length 19.91mm, Mylar Tape Carrier

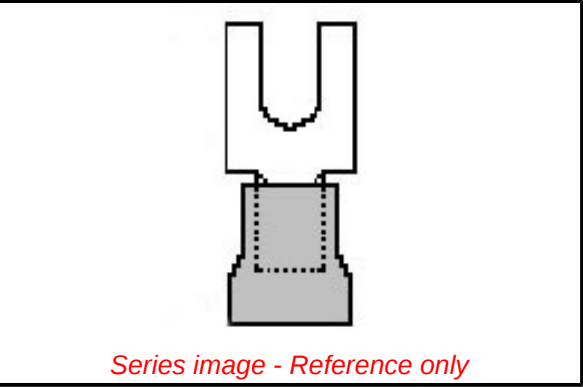

Documents:

Drawing (PDF)

Product Specification PS-19902-009-001 (PDF)

Product Specification PS-19902-011-001 (PDF)

Product Specification PS-19902-015-001 (PDF)

RoHS Certificate of Compliance (PDF)

Agency Certification	
CSA	LR18689
UL	E32244
General	
Product Family	Ring and Spade Terminals
Series	19131
Crimp Quality Equipment	Yes
Overview	Solderless Terminals
Product Name	InsulKrimp
Type	Spade Block
UPC	800753101531
Physical	
Barrel Type	Closed
Color - Resin	Natural
Flammability	94V-0
Insulation	PVC
Material - Plating Mating	Tin
Net Weight	0.554/g
Packaging Type	Adhesive Tape on Reel
Stud Size	5-6 (M3-3.5)
Termination Interface: Style	Crimp or Compression
Wire Insulation Diameter	3.70mm max.
Wire Size AWG	18, 20, 22
Wire Size mm²	0.35-0.80
Material Info	
Engineering Number	AA-238-06XT
Reference - Drawing Numbers	
Product Specification	PS-19902-009-001, PS-19902-011-001, PS-19902-015-001
Sales Drawing	191310039-000

EU ELV

Not Relevant

EU RoHS

Compliant

China RoHS

REACH SVHC

Not Contained Per -

D(2021)4569-DC (8

July 2021)

Halogen-Free

Status

Not Low-Halogen

For more information, please visit

Contact US

China ROHS

Green Image

ELV

Not Relevant

RoHS Phthalates

Not Contained

Search Parts in this Series

19131 Series

Application Tooling | FAQ

Tooling specifications and manuals are found by selecting the products below. Crimp Height Specifications are then contained in the Application Tooling Specification document.

Global	
Description	Product #
ATP Crimp Dies for the Tape Crimp Module and ATP-101 & 301 Press	192880023
FineAdjust Pneumatic Applicator for Ring and Spade Terminals, 18-22 AWG	638851300

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[19131-0030](#)