

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: 0191390006
Status: Active
Overview: Solderless Terminals
Description: Avikrimp Block Spade Terminal for 18-22 AWG Wire

Documents:
[Drawing \(PDF\)](#) [Product Specification PS-19902-013-001 \(PDF\)](#)
[Product Specification PS-19902-011-001 \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)


Agency Certification
CSA LR18689
UL E32244

General
Product Family Ring and Spade Terminals
Series 19139
Crimp Quality Equipment Yes
Overview Solderless Terminals
Product Name Avikrimp
Type Spade Block
UPC 800753102484

Physical
Barrel Type Closed
Flammability 94V-2
Insulation Nylon (PA)
Material - Plating Mating Tin
Net Weight 0.831/g
Packaging Type Bag
Plating min - Mating 2.540µm
Plating min - Termination 2.540µm
Stud Size 5-6 (M3-3.5)
Termination Interface: Style Crimp or Compression
Wire Insulation Diameter 3.60mm max.
Wire Size AWG 18, 20, 22
Wire Size mm² 0.35-0.80

Material Info
Engineering Number AA-8118-06

Reference - Drawing Numbers
Product Specification PS-19902-011-001, PS-19902-013-001
Sales Drawing 195-08, SD-19139-004-001

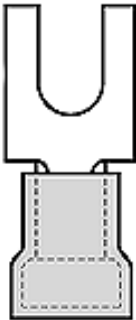

Series image - Reference only

EU ELV
Not Relevant

EU RoHS **China RoHS**
Compliant

REACH SVHC
Contained Per -
D(2021)4569-DC (8
July 2021)
Benzo(ghi)perylene
Octanoic acid,
2,2,3,3,4,4,5,5,6,6,7,7,8,8,8-
pen
Dodecamethylcyclhexasiloxane
Decamethylcyclpentasiloxane
Octamethylcycltetrasiloxane
Disodium 3,3'-[[1,1'-
Biphenyl]-4,4'-
Diylbis(Azo)
1,2-
Benzenedicarboxylic
acid, bis(3-
methylbutyl)
1,2-diethoxyethane
Dibutyltin-dichloride
C.I. Direct Black 38
Ammonium-
pentadecafluorooctanoate
Phenol, 2-(2H-
benzotriazol-2-yl)-4,6-
bis(1,1-dim
2-ethylhexyl 10-
ethyl-4,4-dioctyl-7-
oxo-8-oxa-3,
Dibutylbis(pentane-2,4-
dionato-O,O')tin
2-(2H-Benzotriazol-2-
yl)-4,6-
ditertpentylphenol
2-(2H-Benzotriazol-2-
yl)-4-(tert-butyl)-6-
(sec-b
1,2-
Benzenedicarboxylic

acid, dihexyl ester,
bra
diisohexyl phthalate
1,2-
Benzenedicarboxylic
acid, dipentyl ester, br
Zirconia
Aluminosilicate
Refractory Ceramic
Fibr
Nonadecafluorodecanoic
acid (PFDA) and its
sodiu
Tris(4-nonylphenyl,
branched and linear)
phosphi
Perfluorobutane
sulfonic acid (PFBS)
and its sal
Fluoranthene
Pyrene
Dodecachloropentacyclo[12.2.1.16,9.02,13.05,10]o
Dioctyltin dilaurate,
stannane, dioctyl-,
bis(co
Perfluorononan-1-
oic acid
(2,2,3,3,4,4,5,5,6,6,7
Perfluorohexane-1-
sulphonic acid and its
salts
Dipentyl phthalate
Cobalt-dichloride
Alkanes, C10-13,
chloro
Bis(tributyltin) oxide
Lead chromate
Lead chromate
molybdate sulfate red
Tris(2-chloroethyl)
phosphate
bis(2-methoxyethyl)
ether
1,2-Dimethoxyethane
1,2-bis(2-
methoxyethoxy)ethane
Decabromodiphenylether
Diboron-trioxide
Cadmium-oxide
Lead(II,IV)-oxide
Lead
Cadmium
Lead-dinitrate
Lead-titanium-trioxide
Pentalead-tetraoxide-
sulphate
Tetralead-trioxide-
sulphate
Dioxobis(stearato)trilead
Lead titanium
zirconium oxide
Cyanamide, lead(2+)
salt (1:1)
Sulfurous Acid, Lead
Salt, Dibasic

Silicic acid (H2Si2O5),
barium salt (1:1),
lead-
[Phthalato(2-)]dioxotrilead
4-aminoazobenzene
N,N-
Dimethylformamide
Phenanthrene
Imidazolidine-2-thione
Halogen-Free
Status
Low-Halogen
For more information, please visit [Contact US](#)

China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series
[19139](#) Series

Application Tooling | **FAQ**
Tooling specifications and manuals are found by selecting the products below. Crimp Height Specifications are then contained in the Application Tooling Specification document.
Global

Description	Product #
PremiumGrade Hand Crimp Tool for Avikrimp and Insulkrimp Terminals and Splices, 10-22 AWG and 6.0-0.5mm² (Rings, Spades, Hooks, Block Spades and Flanged Spades) Crimp Head for the AT-200 Pneumatic Hand Tool	640010100
ServiceGrade Hand Crimp Tool for Field Repair only, for production use our PremiumGrade Tool	640050100 640160036

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[19139-0006](#)