

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0191410020

Status:

Active

Overview:

Solderless Terminals

Description:

Krimptite Spade Tongue Terminal for 18-22 AWG Wire, Stud Size 6 (M3.5)

Documents:


Drawing (PDF)

Product Specification PS-19902-011-001 (PDF)

Product Specification PS-19902-013-001 (PDF)

RoHS Certificate of Compliance (PDF)

Agency Certification		
CSA		LR18689
UL		E32244
General		
Product Family		Ring and Spade Terminals
Series		19141
Crimp Quality Equipment		Yes
Overview		Solderless Terminals
Product Name		Krimptite
Type		Spade
UPC		800755086379
Physical		
Barrel Type		Closed
Insulation		None
Material - Plating Mating		Tin
Net Weight		0.561/g
Packaging Type		Bag
Stud Size		6 (M3.5)
Wire Size AWG		18, 20, 22
Wire Size mm²		0.25-1.50
Electrical		
Voltage - Maximum		600V
Material Info		
Engineering Number		AA-135-06
Reference - Drawing Numbers		
Product Specification		PS-19902-011-001, PS-19902-013-001
Sales Drawing		AACD10303-001

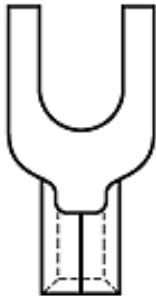

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

China RoHS

REACH SVHC

Contained Per -
D(2021)4569-DC (8
July 2021)
Disodium 3,3'-[[1,1'-
Biphenyl]-4,4'-
Diylbis(Azo)
1,2-
Benzenedicarboxylic
acid, bis(3-
methylbutyl)
1,2-diethoxyethane
Dibutyltin-dichloride
1,3-Propanesultone
C.I. Direct Black 38
Ammonium-
pentadecafluorooctanoate
Disodium-octaborate
2-ethylhexyl 10-
ethyl-4,4-dioctyl-7-
oxo-8-oxa-3,
2-(2H-Benzotriazol-2-
yl)-4-(tert-butyl)-6-
(sec-b
Terphenyl,
hydrogenated
1,2-
Benzenedicarboxylic
acid, dihexyl ester,
bra
1,2-
Benzenedicarboxylic
acid, dipentyl ester, br
n-pentyl-
isopentylphthalate
Boric acid
Aluminosilicate
Refractory Ceramic
Fibres

Zirconia
Aluminosilicate
Refractory Ceramic
Fibr
Perfluorobutane
sulfonic acid (PFBS)
and its sal
Fluoranthene
Dodecachloropentacyclo[12.2.1.16,9.02,13.05,10]o
Diocetyl tin dilaurate,
stannane, dioctyl-,
bis(co
Perfluorononan-1-
oic acid
(2,2,3,3,4,4,5,5,6,6,7
Methylhexahydrophthalic
anhydride
reaction mass of
2-ethylhexyl 10-
ethyl-4,4-dioct
Perfluorohexane-1-
sulphonic acid and its
salts
Dodecamethylcyclohexasiloxane
Diarsenic-trioxide
Lead chromate
Lead chromate
molybdate sulfate red
Tris(2-chloroethyl)
phosphate
bis(2-methoxyethyl)
ether
Potassium
hydroxyoctaoxodizincatedichromate
Pentazinc-chromate-
octahydroxide
1,2-
Benzenedicarboxylic
acid, bis(2-
methoxyethyl
1,2-Dimethoxyethane
Diboron-trioxide
Cadmium-oxide
Cadmium-sulphide
Lead(II,IV)-oxide
Lead
Cadmium
pyrochlore, antimony
lead yellow
Lead-titanium-trioxide
Pentalead-tetraoxide-
sulphate
Trilead-dioxide-
phosphonate
Tetralead-trioxide-
sulphate
Dioxobis(stearato)trilead
Lead titanium
zirconium oxide
Fatty Acids, C16-18,
Lead Salts
Dicyclohexyl-
phthalate

bis(2-(2-methoxyethoxy)ethyl)
ether
Halogen-Free
Status
Low-Halogen

For more information, please visit [Contact US](#)

China ROHS
ELV
RoHS Phthalates

Green Image
Not Relevant
Not Contained

Search Parts in this Series
[19141](#) Series

Application Tooling | [FAQ](#)
Tooling specifications and manuals are found by selecting the products below. Crimp Height Specifications are then contained in the Application Tooling Specification document.
Global

Description	Product #
PremiumGrade Hand Crimp Tool for Krimptite/Versakrimp Terminals and Splices, 10-22 AWG and 6.0mm² - 0.5mm²	640030100
Crimp Head for the AT-200 Pneumatic Hand Tool	640070100
ServiceGrade Hand Crimp Tool - Ratchet	640160038

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[19141-0020](#)