

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0191410023](#)
Status: **Active**
Overview: [Solderless Terminals](#)
Description: Krimptite Spade Tongue Terminal for 18-22 AWG Wire, Stud Size 8 (M4), Mylar Tape Carrier

Documents:
[Drawing \(PDF\)](#) [Product Specification PS-19902-015-001 \(PDF\)](#)
[Product Specification PS-19902-011-001 \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification
CSA LR18689
UL E32244


General
Product Family Ring and Spade Terminals
Series [19141](#)
Crimp Quality Equipment Yes
Overview [Solderless Terminals](#)
Product Name Krimptite
Type Spade
UPC 800753103207

Physical
Barrel Type Closed
Insulation None
Material - Plating Mating Tin
Net Weight 0.374/g
Packaging Type Adhesive Tape on Reel
Stud Size 8 (M4)
Wire Size AWG 18, 20, 22
Wire Size mm² 0.25-1.50

Electrical
Voltage - Maximum 600V

Material Info
Engineering Number AA-135-08T

Reference - Drawing Numbers
Product Specification PS-19902-011-001, PS-19902-015-001
Sales Drawing AACD10303-001

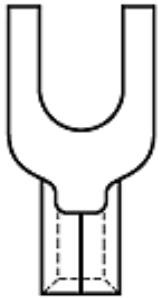

Series image - Reference only

EU ELV
Not Relevant

EU RoHS **China RoHS**
Compliant
REACH SVHC
Not Contained Per -
D(2021)4569-DC (8
July 2021)
Halogen-Free
Status
Low-Halogen

For more information, please visit [Contact US](#)

China ROHS	Not Relevant
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series
[19141 Series](#)

Application Tooling | FAQ
Tooling specifications and manuals are found by selecting the products below. Crimp Height Specifications are then contained in the Application Tooling Specification document.

Global Description	Product #
ATP Crimp Dies for the Tape Crimp Module and ATP-101 & 301 Press	190270034
Mini-Mac Applicator	638853800

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[19141-0023](#)