

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0191600042](#)
Status: **Active**
Overview: [Splices](#)
Description: Twist Lock Splice for 10-22 AWG Wire, Yellow

Documents:
[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)
[Product Specification PS-19902-013-001 \(PDF\)](#)

Agency Certification
CSA LR700095
UL E32244


General
Product Family Splices
Series [19160](#)
Crimp Quality Equipment Yes
Overview [Splices](#)
Product Name Closed-End Twist Lock
UPC 800753110465

Physical
Barrel Type Closed
Color - Resin Yellow
Flammability 94V-2
Insulation Nylon (PA)
Material - Metal Copper
Material - Plating Mating Tin
Material - Plating Termination Tin
Net Weight 1.984/g
Packaging Type Bag
Temperature Range - Operating 105°C
Wire Insulation Diameter 11.18mm max.
Wire Size AWG 10, 12, 14, 16, 18, 20, 22, 24, 26

Electrical
Voltage - Maximum 600V

Material Info
Engineering Number TL-Y

Reference - Drawing Numbers
Product Specification PS-19902-013-001
Sales Drawing SD-19160-005-001

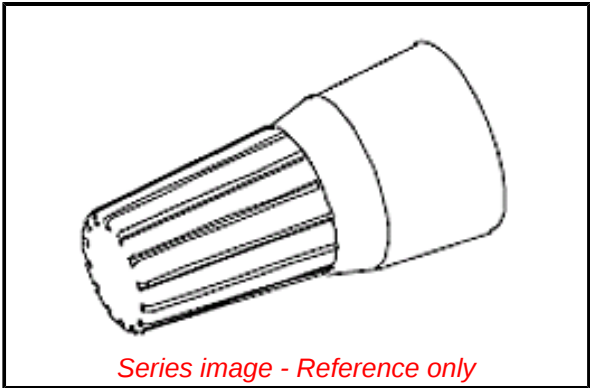

Series image - Reference only

EU ELV
Not Relevant

EU RoHS Compliant REACH SVHC Not Contained Per - D(2021)4569-DC (8 July 2021) Halogen-Free Status Low-Halogen For more information, please visit Contact US	China RoHS China ROHS Green Image ELV Not Relevant RoHS Phthalates Not Contained
--	--

Search Parts in this Series
[19160 Series](#)

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Molex:

19160-0042