

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0191600044

Status:

Active

Overview:

[Splices](#)

Description:

Wing Lock Splice for 10-18 AWG Wire, Yellow


Documents:

[Drawing \(PDF\)](#)

[RoHS Certificate of Compliance \(PDF\)](#)

[Product Specification PS-19902-013-001 \(PDF\)](#)

Agency Certification		
CSA		LR18689
UL		E32244
General		
Product Family		Splices
Series		19160
Crimp Quality Equipment		Yes
Overview		Splices
Product Name		Wing Lock
UPC		800753110489
Physical		
Barrel Type		Closed
Color - Resin		Yellow
Flammability		94V-2
Insulation		Nylon (PA)
Material - Metal		Copper
Material - Plating Mating		Tin
Material - Plating Termination		Tin
Net Weight		1.830/g
Packaging Type		Bag
Temperature Range - Operating		105°C
Wire Insulation Diameter		9.91mm max.
Wire Size AWG		10, 12, 14, 16, 18
Electrical		
Voltage - Maximum		600V
Material Info		
Engineering Number		WL-Y
Reference - Drawing Numbers		
Product Specification		PS-19902-013-001
Sales Drawing		SD-19160-003-001

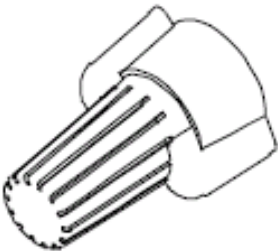

Series image - Reference only

EU ELV	
Not Relevant	
EU RoHS	China RoHS
Compliant	
REACH SVHC	
Not Contained Per - D(2021)4569-DC (8 July 2021)	
Halogen-Free	
Status	
Low-Halogen	
For more information, please visit Contact US	
China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

[19160](#) Series

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[19160-0044](#)