

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: 0191790011

Status: Active

Overview: Solderless Terminals

Description: Avikrimp Hook Tongue Terminal for 14-16 AWG Wire, Stud Size 8 (M4)

Documents:

Drawing (PDF)	Product Specification PS-19902-011-001 (PDF)
Product Specification PS-19902-009-001 (PDF)	RoHS Certificate of Compliance (PDF)

Agency Certification

CSA	LR18689
UL	E32244

General

Product Family	Ring and Spade Terminals
Series	19179
Crimp Quality Equipment	Yes
Overview	Solderless Terminals
Product Name	Avikrimp
Type	Hook
UPC	800753035805

Physical


Barrel Type	Closed
Flammability	94V-0
Insulation	Nylon (PA)
Material - Plating Mating	Tin
Net Weight	0.817/g
Packaging Type	Adhesive Tape on Reel
Stud Size	8 (M4)
Termination Interface: Style	Crimp or Compression
Wire Insulation Diameter	4.45mm max
Wire Size AWG	14, 16
Wire Size mm²	1.00-2.50

Material Info

Engineering Number	BB-219-08XT
--------------------	-------------

Reference - Drawing Numbers

Product Specification	PS-19902-009-001, PS-19902-011-001
Sales Drawing	BBCD20102-001

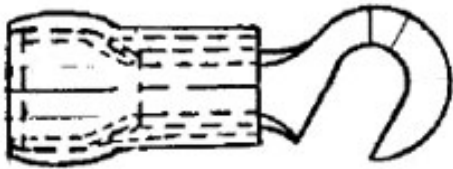

Series image - Reference only

EU ELV
Not Relevant

EU RoHS **China RoHS**
Not Reviewed
REACH SVHC
Not Contained Per
-ED/01/2018 (15
January 2018)
Halogen-Free
Status
Not Low-Halogen
For more information, please visit [Contact US](#)

China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series
19179 Series

Application Tooling | FAQ
Tooling specifications and manuals are found by selecting the products below. Crimp Height Specifications are then contained in the Application Tooling Specification document.
Global

Description	Product #
ATP Crimp Dies for the Tape Crimp Module and ATP-101 & 301 Press	192880123
Mini-Mac Applicator	638850400

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[19179-0011](#)