

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0191790014

Status:

Active

Description:

HOOK INSULKRIMP (C-211-06X)

Documents:

- Drawing (PDF)

Product Specification PS-19902-013-001 (PDF)
- Product Specification PS-19902-009-001 (PDF)

RoHS Certificate of Compliance (PDF)
- Product Specification PS-19902-011-001 (PDF)

Agency Certification

CSA

LR18689

UL

E32244

General

Product Family

Ring and Spade Terminals

Series

19179

Crimp Quality Equipment

Yes

UPC

800753035850

Physical

Flammability

94V-0

Net Weight

1.804/g

Material Info


Engineering Number

C-211-06X

Reference - Drawing Numbers

Product Specification

PS-19902-009-001, PS-19902-011-001,  
PS-19902-013-001

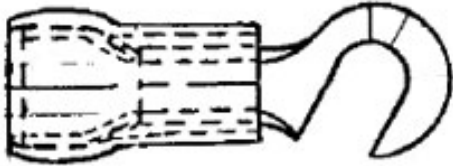

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

China RoHS

REACH SVHC

Not Contained Per -  
D(2021)4569-DC (8  
July 2021)

Halogen-Free

Status

Not Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

Green Image

ELV

Not Relevant

RoHS Phthalates

Not Contained

Search Parts in this Series

19179 Series

Application Tooling | [FAQ](#)

Tooling specifications and manuals are found by selecting the products below. Crimp Height Specifications are then contained in the Application Tooling Specification document.

Global

| Description                                                                                                                                                                                 | Product # |
|---------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------|-----------|
| PremiumGrade<br>Hand Crimp Tool<br>for Avikrimp and<br>Insulkrimp Terminals<br>and Splices,<br>10-22 AWG and<br>6.0-0.5mm² (Rings,<br>Spades, Hooks,<br>Block Spades and<br>Flanged Spades) | 640010100 |
| PremiumGrade<br>Hand Crimp Tool for<br>Insulkrimp Terminals<br>and Splices, 10-22                                                                                                           | 640010300 |

AWG (Rings,  
Spades, Hooks,  
Block Spades and  
Flanged Spades)  
Crimp Head for the 640050100  
AT-200 Pneumatic  
Hand Tool  
Crimp Head for the 640050300  
AT-200 Pneumatic  
Hand Tool  
ServiceGrade Hand 640160036  
Crimp Tool for Field  
Repair only, for  
production use our  
PremiumGrade Tool

This document was generated on 08/26/2021  
**PLEASE CHECK [WWW.MOLEX.COM](http://WWW.MOLEX.COM) FOR LATEST PART INFORMATION**

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[19179-0014](#)