

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:0191930336

Status:Active

Description:RING VERSAKRIMP (H-382-12) SPM

Documents:

Drawing (PDF)Product Specification PS-19902-013-001 (PDF)

Product Specification PS-19902-011-001 (PDF)RoHS Certificate of Compliance (PDF)

Agency Certification

CSALR18689

ULE32244

General

Product FamilyRing and Spade Terminals

Series19193

Crimp Quality EquipmentYes

UPC800755052121

Physical

Net Weight30.562/g

Plating min: Mating (µin)100

Plating min: Mating (µm)2.5

Plating min: Termination (µin)100

Plating min: Termination (µm)2.5

Solder Process Data

Lead-freeProcess Capability

N/A

Material Info


Engineering Number

H-382-12

Reference - Drawing Numbers

Product SpecificationPS-19902-011-001, PS-19902-013-001

Sales DrawingSD-19193-021-001

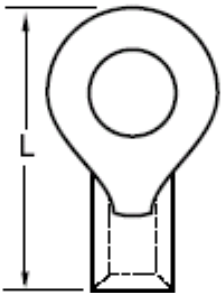

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

China RoHS

REACH SVHC

Not Contained Per -
D(2021)4569-DC (8
July 2021)

Halogen-Free

Status

Low-Halogen

For more information, please visit [Contact US](#)

China ROHSGreen Image

ELVNot Relevant

RoHS PhthalatesNot Contained

Search Parts in this Series

19193 Series

Application Tooling | FAQ

Tooling specifications and manuals are found by selecting the products below. Crimp Height Specifications are then contained in the Application Tooling Specification document.

Global

Description	Product #
Manual Putt Pump Hydraulic System, Die set required	192860117
Die Set (large) for the HHLS Hydraulic Crimper	192900011
Square "Din" Style Die Set for BCL and VersaKrimp Un-insulated Ring Tongue Terminals and Splices, 1/0 and 2/0 AWG	640038070

This document was generated on 09/14/2021

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Molex:

19193-0336