

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0192130012](#)
Status: **Active**
Overview: [Wire Pins](#)
Description: Avikrimp Wire Pin Terminal for 16-14 AWG Wire, Mylar Tape Carrier

Documents:	
3D Model	Product Specification PS-19902-011-001 (PDF)
3D Model (PDF)	Product Specification PS-19902-015-001 (PDF)
Drawing (PDF)	RoHS Certificate of Compliance (PDF)

Agency Certification

CSA	LR18689
UL	E32244

General

Product Family	Crimp Terminals
Series	19213
Application	Power, Wire-to-Component
Comments	Pin Length 9.40mm
Crimp Quality Equipment	Yes
Overview	Wire Pins
Packaging Alternative	192130011 (Loose)
Product Name	Wire Pin
UPC	800753053526

Physical


Flammability	94V-2
Gender	Male
Material - Metal	Copper
Material - Plating Mating	Tin
Net Weight	0.996/g
Packaging Type	Adhesive Tape on Reel
Plating min - Mating	1.016µm
Termination Interface: Style	Crimp or Compression
Wire Insulation Diameter	4.32mm max.
Wire Size AWG	14, 16
Wire Size mm²	N/A

Material Info

Engineering Number	WP-8614T
--------------------	----------

Reference - Drawing Numbers

Product Specification	PS-19902-011-001, PS-19902-015-001
Sales Drawing	SD-19213-002-001

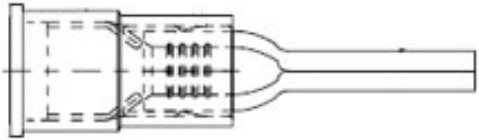

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -
D(2021)4569-DC (8
July 2021)

Halogen-Free

Status

Low-Halogen

For more information, please visit [Contact US](#)

China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

[19213](#) Series

Application Tooling | [FAQ](#)

Tooling specifications and manuals are found by selecting the products below. Crimp Height Specifications are then contained in the Application Tooling Specification document.

Global

Description	Product #
ATP Crimp Dies for the Tape Crimp Module and ATP-101 & 301 Press	192880123
Mini-Mac Applicator	638850400

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Molex:

19213-0012