

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0192160002

Status:


Active

Overview:

Splices

Description:

Multi-Lock Connector for 10-12 AWG Wire

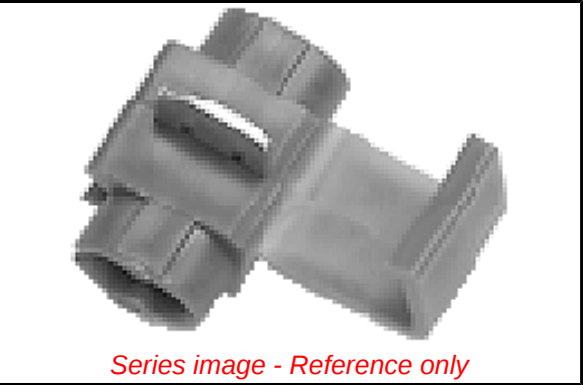

Series image - Reference only

Documents:	
3D Model	Product Specification PS-19902-011-001 (PDF)
3D Model (PDF)	Product Specification PS-19902-013-001 (PDF)
Drawing (PDF)	RoHS Certificate of Compliance (PDF)

Agency Certification	
UL	E32244
General	
Product Family	Splices
Series	19216
Comments	17.78 x 12.70mm when closed
Crimp Quality Equipment	Yes
Overview	Splices
Product Name	Multi-Lock
UPC	800753056107
Physical	
Barrel Type	Closed
Color - Resin	Yellow
Flammability	94V-0
Insulation	Polypropylene
Material - Metal	Copper
Material - Plating Mating	Tin
Material - Plating Termination	Tin
Net Weight	2.900/g
Packaging Type	Bag
Temperature Range - Operating	105°C
Wire Insulation Diameter	4.83mm & 4.32mm
Wire Size AWG	10, 12
Wire Size mm²	N/A
Electrical	
Voltage - Maximum	600V
Solder Process Data	
Lead-freeProcess Capability	N/A
Material Info	
Engineering Number	ML-1210
Reference - Drawing Numbers	
Product Specification	PS-19902-011-001, PS-19902-013-001
Sales Drawing	SD-19216-003-001

EU ELV	
Not Relevant	
EU RoHS	China RoHS
Compliant	
REACH SVHC	
Not Contained Per - D(2021)4569-DC (8 July 2021)	
Halogen-Free	
Status	
Low-Halogen	
For more information, please visit Contact US	
China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

19216 Series

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Molex:

19216-0002