

This document was generated on 10/07/2021

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0192860058](#)


Status: **Active**

Overview: Application Tooling

Description: 12 TON Crimp Head with HHLD Die Holders Only

Documents:

[RoHS Certificate of Compliance \(PDF\)](#)

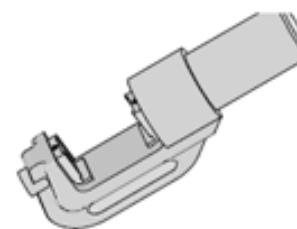

Series image - Reference only

General

Product Family

Application Tooling

Series

[207125](#)

Comments

Type: HYD PRESS

Function

Crimp

Geographic Area

Global

Level of Automation

Manual

[More Detailed Tech Information](#)

[applicationtooling@molex.com](#)

Overview

[Application Tooling](#)

Product Name

N/A

Tool Type

Hydraulic Press

UPC

800753106857

Warranty Disclaimer

CAUTION: Molex tooling crimp specifications are valid only when used with Molex terminals and tooling manufactured by Molex and sold by Molex or authorized distributors ("Molex Tooling"). When using tooling other than Molex Tooling with Molex specific connector systems listed in our ATS documents, the Molex tooling qualification does not apply and the responsibility for full qualification of the connector system is that of the customer. Molex accepts no liability for connector performance or tooling support where tooling other than Molex Tooling is used or where Molex Tooling is modified.

Material Info

Engineering Number

HHLS

Reference - Drawing Numbers

Application Tooling Documents

ATS-192860058-001, TM-192861300-001

EU ELV

Not Reviewed

EU RoHS

Not Reviewed

China RoHS

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

For more information, please visit [Contact US](#)

China ROHS

Not Reviewed

ELV

Not Reviewed

RoHS Phthalates

Not Reviewed

Search Parts in this Series

207125 Series

This document was generated on 10/07/2021

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex](#):

[19286-0058](#)