

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION


Part Number: [0192900007](#)
Status: **Active**
Overview: [Application Tooling](#)
Description: Die Set (large) for the HHLS Hydraulic Crimper

Documents:
[RoHS Certificate of Compliance \(PDF\)](#)

General	
Product Family	Application Tooling
Series	207122
Function	Crimp
Geographic Area	Global
Level of Automation	Manual
More Detailed Tech Information	applicationtooling@molex.com
Overview	Application Tooling
Product Name	ETC
Tool Type	Crimp Module
UPC	800753111752
Warranty Disclaimer	CAUTION: Molex tooling crimp specifications are valid only when used with Molex terminals and tooling manufactured by Molex and sold by Molex or authorized distributors ("Molex Tooling"). When using tooling other than Molex Tooling with Molex specific connector systems listed in our ATS documents, the Molex tooling qualification does not apply and the responsibility for full qualification of the connector system is that of the customer. Molex accepts no liability for connector performance or tooling support where tooling other than Molex Tooling is used or where Molex Tooling is modified.

Material Info	
Engineering Number	HHL-F-130

Reference - Drawing Numbers	
Application Tooling Documents	ATS-192900007-001, TM-640160065-001, TM-640160065CN-001, TM-640160065DE-001, TM-640160065FR-001, TM-640160065IT-001, TM-640160065JP-001, TM-640160065KR-001, TM-640160065MY-001, TM-640160065PL-001, TM-640160065RU-001, TM-640160065SK-001, TM-640160065SP-001, TM-640160065TH-001, TM-640160065TW-001, TM-640160065VN-001

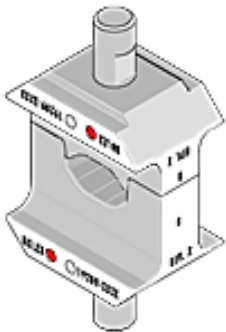

Series image - Reference only

EU ELV Not Reviewed	
EU RoHS Not Reviewed REACH SVHC Not Reviewed Halogen-Free Status Not Reviewed	China RoHS
For more information, please visit Contact US	
China ROHS	Not Reviewed
ELV	Not Reviewed
RoHS Phthalates	Not Reviewed

Search Parts in this Series
[207122 Series](#)

Use With
Molex HHLS Air Powered Hydraulic Crimper 12 Ton [192860058](#) , Manual Putt Pump Hydraulic System [192860117](#) , Electric Powered Hydraulic System [192861300](#)

Application Tooling Description	FAQ Product #
VersaKrimp Ring Tongue Terminal for 4 AWG Wire	191930254
VersaKrimp Ring Tongue Terminal for 4 AWG Wire	191930258
VersaKrimp Ring Tongue Terminal for 4 AWG Wire	191930261
VersaKrimp Ring Tongue Terminal for 4 AWG Wire	191930264
VersaKrimp Ring Tongue Terminal for 4 AWG Wire	191930267

	VersaKrimp Ring Tongue Terminal for 4 AWG Wire	191930273
	VersaKrimp Ring Tongue Terminal for 4 AWG Wire	191930275
	VersaKrimp Ring Tongue Terminal for 4 AWG Wire	191930278
	VersaKrimp Ring Tongue Terminal for 4 AWG Wire	191930281
	VersaKrimp Ring Tongue Terminal for 4 AWG Wire	191930283
	VersaKrimp Ring Tongue Terminal for 4 AWG Wire	191930285
	VersaKrimp Ring Tongue Terminal for 4 AWG Wire	191930293
	VersaKrimp Parallel Splice for 4 AWG Wire	192050007
	VersaKrimp Butt Splice for 4 AWG Wire	192150045
	Compression Style Ring Tongue Terminal for 4 AWG Wire, Stud Size 1/4" (M6), Tin Plated	192210230
	Compression Style Ring Tongue Terminal for 4 AWG Wire, Stud Size 5/16" (M8), Tin Plated	192210231
	Compression Style Ring Tongue Terminal for 4 AWG Wire, Stud Size 3/8" (M9), Tin Plated	192210232
	Compression Style Ring Tongue Terminal for 4 AWG Wire, Stud Size 3/8" (M9), Unplated	192210383
	Compression Style Ring Tongue Terminal for 4 AWG Wire, Stud Size 1/4" (M6), Unplated	192210404
	Compression Style Ring Tongue Terminal for 4 AWG Wire, Stud Size 5/16" (M8), Unplated	192210405
	Compression Style Ring Tongue Terminal for 4 AWG Wire, Stud Size 10 (M5), Unplated	192210451
	Compression Style Ring Tongue	192210452

Terminal for 4 AWG Wire, Stud Size 10 (M5), Tin Plated Compression	<u>192210453</u>
Style Ring Tongue Terminal for 4 AWG Wire, Stud Size 1/2" (M12), Unplated Compression	<u>192210454</u>
Style Ring Tongue Terminal for 4 AWG Wire, Stud Size 1/2" (M12), Tin Plated Compression	<u>192210456</u>
Style Ring Tongue Terminal for 4 AWG Wire, Stud Size 3/8" (M9), Tin Plated, Wide Pad Compression	<u>192210458</u>
Style Ring Tongue Terminal for 4 AWG Wire, Stud Size 3/8" (M9), Unplated, Wide Pad Compression	<u>192210459</u>
Style Ring Tongue Terminal for 4 AWG Wire, Stud Size 3/8" (M9), Unplated, Extra Wide Pad Compression	<u>192210460</u>
Style Ring Tongue Terminal for 4 AWG Wire, Stud Size 5/16" (M8), Tin Plated, Wide Pad Compression	<u>192210461</u>
Style Ring Tongue Terminal for 4 AWG Wire, Stud Size 5/16" (M8), Unplated, Wide Pad	

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[19290-0007](#)