

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0192900010

Status:

Active

Overview:

Application Tooling

Description:

Die Set (large) for the HHLS Hydraulic Crimper

Documents:

RoHS Certificate of Compliance (PDF)

General	
Product Family	Application Tooling
Series	207125
Function	Crimp
Geographic Area	Global
Level of Automation	Manual
More Detailed Tech Information	applicationtooling@molex.com
Overview	Application Tooling
Product Name	ETC
Tool Type	Crimp Module
UPC	800753111769
Warranty Disclaimer	CAUTION: Molex tooling crimp specifications are valid only when used with Molex terminals and tooling manufactured by Molex and sold by Molex or authorized distributors ("Molex Tooling"). When using tooling other than Molex Tooling with Molex specific connector systems listed in our ATS documents, the Molex tooling qualification does not apply and the responsibility for full qualification of the connector system is that of the customer. Molex accepts no liability for connector performance or tooling support where tooling other than Molex Tooling is used or where Molex Tooling is modified.

Material Info


Engineering Number

HHL-G-140

Reference - Drawing Numbers

Application Tooling Documents

ATS-192900010-001, TM-640160065-001, TM-640160065CN-001, TM-640160065DE-001, TM-640160065FR-001, TM-640160065IT-001, TM-640160065JP-001, TM-640160065KR-001, TM-640160065MY-001, TM-640160065PL-001, TM-640160065RU-001, TM-640160065SK-001, TM-640160065SP-001, TM-640160065TH-001, TM-640160065TW-001, TM-640160065VN-001

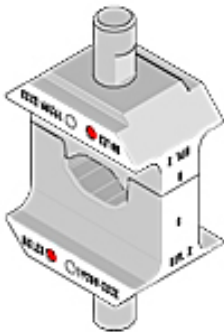

Series image - Reference only

EU ELV	
Not Reviewed	
EU RoHS	China RoHS
Not Reviewed	
REACH SVHC	
Not Reviewed	
Halogen-Free	
Status	
Not Reviewed	
For more information, please visit Contact US	
China ROHS	Not Reviewed
ELV	Not Reviewed
RoHS Phthalates	Not Reviewed

Search Parts in this Series

207125 Series

Use With

Molex HHLS Air Powered Hydraulic Crimper 12 Ton 192860058 , Manual Putt Pump Hydraulic System 192860117 , Electric Powered Hydraulic System 192861300

Application Tooling Description	FAQ Product #
VersaKrimp Ring Tongue Terminal for 2 AWG Wire	191930296
VersaKrimp Ring Tongue Terminal for 2 AWG Wire	191930297
VersaKrimp Ring Tongue Terminal for 2 AWG Wire	191930298
VersaKrimp Ring Tongue Terminal for 2 AWG Wire	191930299
VersaKrimp Ring Tongue Terminal for 2 AWG Wire	191930302

VersaKrimp Ring Tongue Terminal for 2 AWG Wire	<u>191930303</u>
VersaKrimp Ring Tongue Terminal, 2 AWG	<u>191930305</u>
VersaKrimp Ring Tongue Terminal for 2 AWG Wire	<u>191930307</u>
VersaKrimp Ring Tongue Terminal for 2 AWG Wire	<u>191930309</u>
VersaKrimp Ring Tongue Terminal for 2 AWG Wire	<u>191930320</u>
VersaKrimp Parallel Splice for 2 AWG Wire	<u>192050008</u>
VersaKrimp Butt Splice for 2 AWG Wire	<u>192150046</u>
Compression Style Ring Tongue Terminal for 2 AWG Wire, Stud Size 5/16" (M8), Tin Plated	<u>192210233</u>
Compression Style Ring Tongue Terminal for 2 AWG Wire, Stud Size 3/8" (M9), Tin Plated	<u>192210235</u>
Compression Style Ring Tongue Terminal for 2 AWG Wire, Stud Size 3/8" (M9), Unplated	<u>192210380</u>
Compression Style Ring Tongue Terminal for 2 AWG Wire, Stud Size 1/2" (M12), Unplated, Wide Pad	<u>192210399</u>
Compression Style Ring Tongue Terminal for 2 AWG Wire, Stud Size 5/16" (M8), Unplated	<u>192210400</u>
Compression Style Ring Tongue Terminal for 2 AWG Wire, Stud Size 1/4" (M6), Tin Plated	<u>192210418</u>
Compression Style Ring Tongue Terminal for 2 AWG Wire, Stud Size 1/4" (M6), Unplated	<u>192210419</u>
Compression Style Ring Tongue Terminal for 2 AWG Wire, Stud Size 3/8" (M9), Unplated, Wide Pad	<u>192210564</u>

Compression	<u>192210565</u>
Style Ring Tongue	
Terminal for 2 AWG	
Wire, Stud Size	
3/8" (M9), Tin Plated,	
Wide Pad	

This document was generated on 07/27/2021

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Molex:

19290-0010