

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION


Part Number: [0192900011](#)
Status: **Active**
Overview: [Application Tooling](#)
Description: Die Set (large) for the HHLS Hydraulic Crimper

Documents:
[RoHS Certificate of Compliance \(PDF\)](#)

General
Product Family [Application Tooling](#)
Series [207125](#)
Function [Crimp](#)
Geographic Area [Global](#)
Level of Automation [Manual](#)
More Detailed Tech Information [applicationtooling@molex.com](#)
Overview [Application Tooling](#)
Product Name [ETC](#)
Tool Type [Crimp Module](#)
UPC [800753111776](#)
Warranty Disclaimer [CAUTION: Molex tooling crimp specifications are valid only when used with Molex terminals and tooling manufactured by Molex and sold by Molex or authorized distributors \("Molex Tooling"\). When using tooling other than Molex Tooling with Molex specific connector systems listed in our ATS documents, the Molex tooling qualification does not apply and the responsibility for full qualification of the connector system is that of the customer. Molex accepts no liability for connector performance or tooling support where tooling other than Molex Tooling is used or where Molex Tooling is modified.](#)

Material Info
Engineering Number [HHL-H-150](#)

Reference - Drawing Numbers
[Application Tooling Documents](#) [ATS-192900011-001, TM-640160065-001, TM-640160065CN-001, TM-640160065DE-001, TM-640160065FR-001, TM-640160065IT-001, TM-640160065JP-001, TM-640160065KR-001, TM-640160065MY-001, TM-640160065PL-001, TM-640160065RU-001, TM-640160065SK-001, TM-640160065SP-001, TM-640160065TH-001, TM-640160065TW-001, TM-640160065VN-001](#)

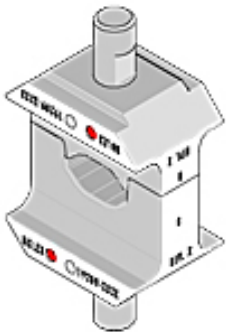

Series image - Reference only

EU ELV
Not Reviewed

EU RoHS **China RoHS**
Not Reviewed
REACH SVHC
Not Reviewed
Halogen-Free
Status
Not Reviewed

For more information, please visit [Contact US](#)

China ROHS	Not Reviewed
ELV	Not Reviewed
RoHS Phthalates	Not Reviewed

Search Parts in this Series
[207125 Series](#)

Use With
Molex HHLS Air Powered Hydraulic Crimper 12 Ton [192860058](#) , Manual Putt Pump Hydraulic System [192860117](#) , Electric Powered Hydraulic System [192861300](#)

Application Tooling Description	FAQ Product #
VersaKrimp Ring Tongue Terminal for 1/0 AWG Wire	191930325
VersaKrimp Ring Tongue Terminal for 1/0 AWG Wire	191930329
VersaKrimp Ring Tongue Terminal for 1/0 AWG Wire	191930330
VersaKrimp Ring Tongue Terminal for 1/0 AWG Wire	191930331
VersaKrimp Ring Tongue Terminal for 1/0 AWG Wire	191930333

	VersaKrimp Parallel Splice for 1/0 AWG Wire	<u>192050009</u>
	VersaKrimp Butt Splice for 1/0 AWG Wire	<u>192150047</u>
	Compression Style Ring Tongue Terminal for 1 AWG Wire, Stud Size 5/16" (M8), Tin Plated	<u>192210237</u>
	Compression Style Ring Tongue Terminal for 1 AWG Wire, Stud Size 3/8" (M9), Tin Plated	<u>192210238</u>
	Compression Style Ring Tongue Terminal for 1 AWG Wire, Stud Size 1/2" (M12), Tin Plated, Wide Pad	<u>192210239</u>
	Compression Style Ring Tongue Terminal for 1/0 AWG Wire, Stud Size 5/16" (M8), Plated	<u>192210240</u>
	Compression Style Ring Tongue Terminal for 1/0 AWG Wire, Stud Size 3/8" (M9), Plated	<u>192210241</u>
	Compression Style Ring Tongue Terminal for 1/0 AWG Wire, Stud Size 1/2" (M12), Plated	<u>192210242</u>
	Compression Style Ring Tongue Terminal for 1/0 AWG Wire, Stud Size 3/8" (M9), Unplated	<u>192210377</u>
	Compression Style Ring Tongue Terminal for 1 AWG Cable, Stud Size 3/8" (M9), Unplated	<u>192210378</u>
	Compression Style Ring Tongue Terminal for 1/0 AWG Wire, Stud Size 1/2" (M12), Unplated	<u>192210393</u>
	Compression Style Ring Tongue Terminal for 1/0 AWG Wire, Stud Size 5/16" (M8), Unplated	<u>192210394</u>

Compression	<u>192210395</u>
Style Ring Tongue	
Terminal for 1 AWG	
Wire, Stud Size	
1/2" (M12), Unplated,	
Wide Pad	
Compression	<u>192210396</u>
Style Ring Tongue	
Terminal for 1 AWG	
Wire, Stud Size	
5/16" (M8), Unplated	
Compression	<u>192210420</u>
Style Ring Tongue	
Terminal for 1 AWG	
Wire, Stud Size	
1/4" (M6), Tin Plated	
Compression	<u>192210421</u>
Style Ring Tongue	
Terminal for 1 AWG	
Wire, Stud Size	
1/4" (M6), Unplated	
Compression	<u>192210422</u>
Style Ring Tongue	
Terminal for 1/0	
AWG Wire, Stud	
Size 1/4" (M6),	
Plated	
Compression	<u>192210423</u>
Style Ring Tongue	
Terminal for 1/0	
AWG Wire, Stud	
Size 1/4" (M6),	
Unplated	
Compression	<u>192210580</u>
Style Ring Tongue	
Terminal for 1 AWG	
Wire, Stud Size	
3/8" (M9), Unplated,	
Wide Pad	
Compression	<u>192210581</u>
Style Ring Tongue	
Terminal for 1 AWG	
Wire, Stud Size	
3/8" (M9), Tin Plated,	
Wide Pad	
Compression	<u>192210594</u>
Style Ring Tongue	
Terminal for 1 AWG	
Cable, Stud Size 10	
(M5), Unplated	
Compression	<u>192210595</u>
Style Ring Tongue	
Terminal for 1 AWG	
Wire, Stud Size 10	
(M5), Tin Plated	

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[19290-0011](#)