

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0194280022](#)
Status: **Active**
Overview: [MX150L Industrial Sealed Connector System](#)
Description: 5.84mm Pitch MX150L Vertical PCB Header, Dual Row, Standard Profile, Gold (Au) Plated, 10 Circuits

Documents:

| | |
|--|--|
| 3D Model | Packaging Specification PK-19428-001-001 (PDF) |
| Drawing (PDF) | Brochure (PDF) |
| 3D Model (PDF) | RoHS Certificate of Compliance (PDF) |
| Product Specification PS-19427-001-001 (PDF) | |

Agency Certification

UL E152602

General


| | |
|----------------|---|
| Product Family | PCB Headers |
| Series | 19428 |
| Application | Power, Wire-to-Board |
| Comments | IP67 rated; conforms to UL 1977. NOT suitable for automotive applications with requirements such as USCAR-2, USCAR-25, GMW3191, AK Testing, J2030, Volvo Technology Requirements, and Toyota Connector Spec (TCS) |
| Overview | MX150L Industrial Sealed Connector System |
| Product Name | MX150L |
| UPC | 822348742998 |

Physical

| | |
|--------------------------------|----------------|
| Breakaway | No |
| Circuits (Loaded) | 10 |
| Circuits (maximum) | 10 |
| Durability (mating cycles max) | 100 |
| Flammability | 94V-0 |
| Glow-Wire Capable | No |
| Lock to Mating Part | Yes |
| Material - Plating Mating | Gold |
| Material - Plating Termination | Tin |
| Net Weight | 21.666/g |
| Number of Rows | 2 |
| Orientation | Vertical |
| PC Tail Length | 3.30mm |
| PCB Locator | Yes |
| PCB Retention | None |
| PCB Thickness - Recommended | 1.60mm |
| Packaging Type | Tray |
| Pitch - Mating Interface | 5.84mm |
| Polarized to Mating Part | Yes |
| Polarized to PCB | Yes |
| Shrouded | Fully |
| Stackable | No |
| Surface Mount Compatible (SMC) | No |
| Temperature Range - Operating | -40° to +125°C |
| Termination Interface: Style | Through Hole |

Electrical

Current - Maximum per Contact 18.0A

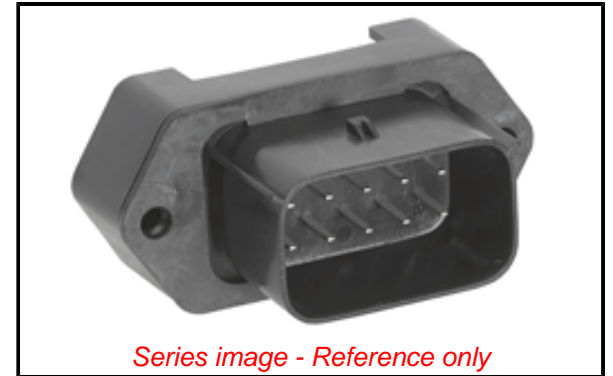

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -
D(2021)4569-DC (8
July 2021)

**Halogen-Free
Status**

Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

China RoHS

Not Relevant

Not Relevant

Not Contained

Search Parts in this Series

[19428](#) Series

Mates With

[19418](#) Receptacle Assemblies

Voltage - Maximum

600V

Material Info

Reference - Drawing Numbers

Packaging Specification

PK-19428-001-001

Product Specification

PS-19427-001-001

Sales Drawing

SD-19428-014-001

This document was generated on 12/27/2021

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[19428-0022](#)