


PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: 0194300003
Status: Active
Overview: Splices
Description: See and Splice 4 Circuit Push-in Wire Connector for 12-22 AWG Wire

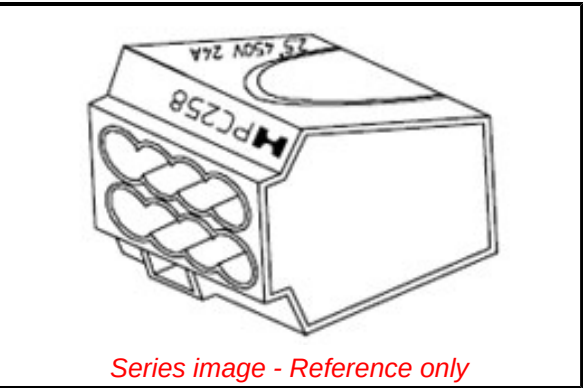

Series image - Reference only

Documents:
[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification	
UL	E32244
General	
Product Family	Splices
Series	19430
Comments	Yellow Insert 1000V max. for lighting/sign fixtures
Crimp Quality Equipment	Yes
Overview	Splices
Product Name	See and Splice
UPC	822348218905
Physical	
Barrel Type	Closed
Color - Resin	Yellow
Flammability	94V-2
Insulation	None
Material - Metal	Brass
Material - Plating Mating	N/A
Net Weight	2.881/g
Packaging Type	Bag
Temperature Range - Operating	-30° to +105°C
Wire Insulation Diameter	3.30mm is the nominal O.D.
Wire Size AWG	12, 14, 16, 18, 20, 22
Electrical	
Voltage - Maximum	600V
Material Info	
Engineering Number	PC4-YELLOW
Reference - Drawing Numbers	
Sales Drawing	SD-19430-001

EU ELV Not Relevant	
EU RoHS Compliant	China RoHS
REACH SVHC Not Contained Per - ED/71/2019 (16 July 2019)	
Halogen-Free Status Low-Halogen	
For more information, please visit Contact US	
China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series
[19430 Series](#)

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[19430-0003](#)