

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0194351212](#)
Status: **Active**
Overview: [MX150L Industrial Sealed Connector System](#)
Description: MX150L 12 Circuit Rear Mount Flange Plug for 18-22 AWG Wire, with Gasket, Black

Documents:
[3D Model](#)
[Drawing \(PDF\)](#)
[3D Model \(PDF\)](#)
[Product Specification PS-19417-001-001 \(PDF\)](#)
[Packaging Specification PK-19435-001-001 \(PDF\)](#)
[Brochure \(PDF\)](#)
[RoHS Certificate of Compliance \(PDF\)](#)


General
Product Family Crimp Housings
Series [19435](#)
Application Power, Wire-to-Wire
Comments Mat Seal Color is Red. IP67 rated; conforms to UL 1977. NOT suitable for automotive applications with requirements such as USCAR-2, USCAR-25, GMW3191, AK Testing, J2030, Volvo Technology Requirements, and Toyota Connector Spec (TCS)
[MX150L Industrial Sealed Connector System](#)
Overview
Product Name MX150L
UPC 822350301091

Physical
Circuits (maximum) 12
Color - Resin Black
Gender Plug
Glow-Wire Capable No
Lock to Mating Part Yes
Number of Rows 2
Packaging Type Bag
Panel Mount Yes
Pitch - Mating Interface 5.84mm
Polarized to Mating Part Yes
Stackable No
Temperature Range - Operating -40° to +125°C

Electrical
Current - Maximum per Contact 18.0A

Material Info

Reference - Drawing Numbers
[Packaging Specification](#) PK-19435-001-001
[Product Specification](#) PS-19417-001-001
[Sales Drawing](#) SD-19435-012-001

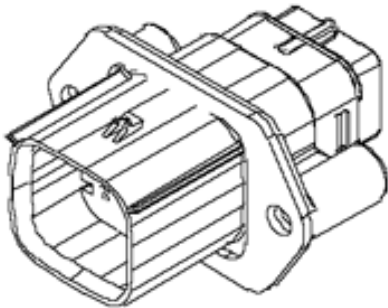

Series image - Reference only

EU ELV
Not Relevant

EU RoHS **China RoHS**
Compliant
REACH SVHC
Not Contained Per -
D(2021)4569-DC (8
July 2021)
Halogen-Free
Status
Low-Halogen
For more information, please visit [Contact US](#)

China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series
[19435](#) Series

Mates With
[19418](#) Receptacle Assemblies

Use With
[19417](#) Male Crimp Terminals

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[19435-1212](#)