


PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0194360414](#)
Status: **Active**
Overview: [MX150L Industrial Sealed Connector System](#)
Description: MX150L 4 Circuit Rear Mount Flange Sealed Panel Mount Plug for 8 AWG Wire, without Gasket, Black

Documents:

| | |
|--|--|
| 3D Model | Packaging Specification PK-19436-001-001 (PDF) |
| 3D Model (PDF) | Brochure (PDF) |
| Drawing (PDF) | RoHS Certificate of Compliance (PDF) |
| Product Specification PS-19432-001-001 (PDF) | |

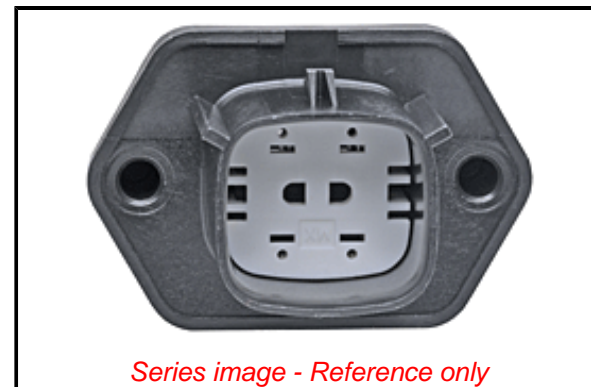

General

| | |
|----------------|---|
| Product Family | Crimp Housings |
| Series | 19436 |
| Application | Power, Wire-to-Wire |
| Comments | Mat Seal Color Red, Polarized to Mating Part. IP67 rated; conforms to UL 1977. NOT suitable for automotive applications with requirements such as USCAR-2, USCAR-25, GMW3191, AK Testing, J2030, Volvo Technology Requirements, and Toyota Connector Spec (T) |
| Overview | MX150L Industrial Sealed Connector System |
| Product Name | MX150L |
| UPC | 800756731858 |

Physical

| | |
|-------------------------------|----------------|
| Circuits (maximum) | 4 |
| Circuits Detail | 2x2 |
| Color - Resin | Black |
| Gender | Plug |
| Glow-Wire Capable | No |
| Keying to Mating Part | N/A |
| Lock to Mating Part | Yes |
| Number of Rows | 2 |
| Packaging Type | Bag |
| Panel Mount | Yes |
| Pitch - Mating Interface | 7.62mm |
| Pitch - Termination Interface | 7.62mm |
| Polarized to Mating Part | No |
| Ports | 1 |
| Stackable | No |
| Temperature Range - Operating | -40° to +125°C |

Electrical

| | |
|-------------------------------|-------|
| Current - Maximum per Contact | 40.0A |
|-------------------------------|-------|

Material Info

Reference - Drawing Numbers

| | |
|-------------------------|------------------|
| Packaging Specification | PK-19436-001-001 |
| Product Specification | PS-19432-001-001 |
| Sales Drawing | SD-19436-002 |

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Contained Per - ED/30/2017 (7 July 2017)
 2,4-Di-tert-butyl-6-(5-chlorobenzotriazol-2-yl)p

Halogen-Free

Status

Not Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

Not Relevant

ELV

Not Relevant

RoHS Phthalates

Not Contained

Search Parts in this Series

[19436](#) Series

Mates With

[19432](#) Receptacle

Use With

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[19436-0414](#)