

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: 0197234103
Status: Active
Overview: Snap Plugs and Receptacles
Description: VibraKrimp Open Barrel Strip Snap Plug Receptacle with Strain Relief

Documents:
[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)
[Packaging Specification PK-19723-001 \(PDF\)](#)


General
Product Family Quick Disconnects
Series 19723
Comments Open Barrel, Open Barrel
Crimp Quality Equipment Yes
Insulated No
Overview Snap Plugs and Receptacles
Product Name VibraKrimp
Type Snap Plug
UPC 800755105001

Physical
Barrel Type Open
Gender Female
Glow-Wire Capable No
Insulation None
Lock to Mating Part None
Material - Metal Brass
Material - Plating Mating Tin
Material - Plating Termination Tin
Net Weight 0.460/g
Orientation Straight
Packaging Type Reel
Plating min - Mating 2.540µm
Plating min - Termination 2.540µm
Tab Thickness N/A
Tab Width N/A
Wire Insulation Diameter N/A
Wire Size AWG 14, 16, 18

Electrical
Voltage - Maximum N/A

Material Info

Reference - Drawing Numbers
Packaging Specification PK-19723-001
Sales Drawing SD-19723-002

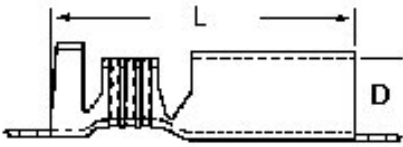

Series image - Reference only

EU ELV
Not Relevant

EU RoHS	China RoHS
Compliant	
REACH SVHC	
Not Contained Per - ED/71/2019 (16 July 2019)	
Halogen-Free	
Status	
Not Relevant	
For more information, please visit Contact US	
China ROHS	Not Relevant
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series
19723 Series

Application Tooling | FAQ
Tooling specifications and manuals are found by selecting the products below. Crimp Height Specifications are then contained in the Application Tooling Specification document.
Global

Description	Product #
Mini-Mac Applicator	638026600
Rear Feed	

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[19723-4103](#)