

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0250010401

Status:


Active

Overview:

Ribbon Cable Jumpers

Description:

2.54mm Pitch Board-to-Board Ribbon Cable Jumper - 26 AWG, Stranded Topcoat, 4 Circuits, Strip and Retain, 0.025m Length

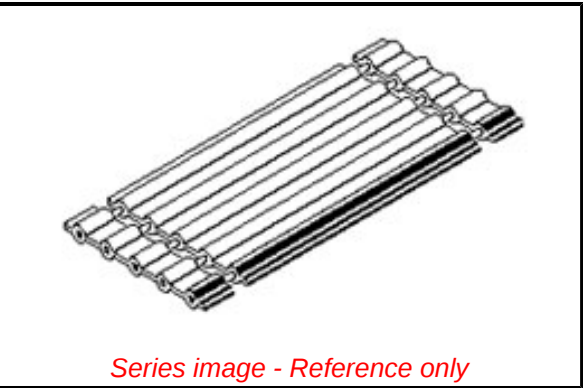

Series image - Reference only

Documents:

Drawing (PDF)

RoHS Certificate of Compliance (PDF)

General	
Product Family	Cable
Series	25001
Crimp Quality Equipment	Yes
Geographic Area	Asia
Overview	Ribbon Cable Jumpers
Product Name	Ribbon
UPC	800754968379
Physical	
Cable Length	0.025m
Circuits (Loaded)	4
Circuits (maximum)	4
Insulation	PVC
Net Weight	0.388/g
Packaging Type	Bag
Pitch - Termination Interface	2.54mm
Temperature Range - Operating	-20°C to +105°C
Wire Size AWG	26
Wire/Cable Type	(7x34) Stranded, Topcoat
Electrical	
Current - Maximum per Contact	N/A
Voltage - Maximum	300V
Material Info	
Reference - Drawing Numbers	
Sales Drawing	SD-25001-001

EU ELV

Not Reviewed

EU RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

Need more information on product environmental compliance?

Email productcompliance@molex.com

Please visit the [Contact Us](#) section for any non-product compliance questions.

China ROHS

Not Reviewed

ELV

Not Reviewed

RoHS Phthalates

Not Reviewed

Search Parts in this Series

25001 Series

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[25001-0401](#)