

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

31408-1121

Status:


Active

Overview:

Stac64™ Single, Multi-Pocket and Hybrid Header System

Description:

USCAR 2.54mm Pitch Receptacle, 12 Circuits, Polarization B, Gray

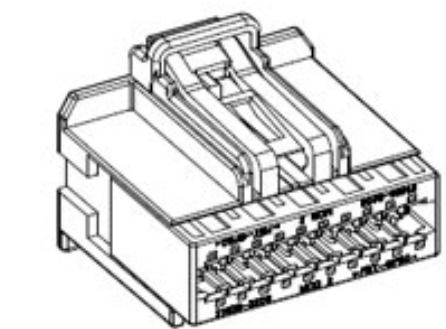

Series

image - Reference only

- Documents:
- 3D Model

Application Specification AS-34691-100 (PDF)
- Drawing (PDF)

RoHS Certificate of Compliance (PDF)
- Product Specification PS-31408-100 (PDF)

General

Product Family	Crimp Housings
Series	31408
Application	Power, Wire-to-Board
Comments	Polarization B
Overview	Stac64™ Single, Multi-Pocket and Hybrid Header System
Product Name	USCAR
UPC	822348633432

Physical

Circuits (maximum)	12
Circuits Detail	12
Color - Resin	Gray
Gender	Female
Glow-Wire Compliant	No
Keying to Mating Part	None
Lock to Mating Part	No
Material - Resin	Modified Polystyrene
Net Weight	4.475/g
Number of Rows	2
Packaging Type	Carton
Panel Mount	No
Pitch - Mating Interface	2.54mm
Polarized to Mating Part	Yes
Ports	1
Stackable	No
Temperature Range - Operating	-40°C to +100°C

Electrical

Current - Maximum per Contact	10.2A
-------------------------------	-------

Material Info

Reference - Drawing Numbers

Application Specification	AS-34691-100
Product Specification	PS-31408-100
Sales Drawing	SD-31408-900

EU RoHS

ELV and RoHS Compliant

REACH SVHC

Not Reviewed

Low-Halogen Status

Low-Halogen

China RoHS



Need more information on product environmental compliance?

Email productcompliance@molex.com
For a multiple part number RoHS Certificate of Compliance, [click here](#)

Please visit the [Contact Us](#) section for any non-product compliance questions.

Search Parts in this Series

31408Series

Mates With

34691 Stac64 Right Angle Assembly. 34690 Stac64 Vertical Assembly

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Molex:

[31408-1120](#) [31408-1121](#) [31408-1160](#)