

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [31408-1161](#)
Status: **Active**
Overview: Stac64™ Single, Multi-Pocket and Hybrid Header System
Description: USCAR 2.54mm Pitch Receptacle, 16 Circuits, Polarization B, Gray

Documents:
[3D Model](#)
[Drawing \(PDF\)](#)
[Product Specification PS-31408-100 \(PDF\)](#)
[Application Specification AS-34691-100 \(PDF\)](#)
[RoHS Certificate of Compliance \(PDF\)](#)


General
Product Family Crimp Housings
Series [31408](#)
Application Power, Wire-to-Board
Comments Polarization B
Overview Stac64™ Single, Multi-Pocket and Hybrid Header System
Product Name USCAR
UPC 822348633500

Physical
Circuits (maximum) 16
Circuits Detail 16
Color - Resin Gray
Gender Female
Glow-Wire Compliant No
Keying to Mating Part None
Lock to Mating Part No
Material - Resin Modified Polystyrene
Net Weight 5.375/g
Number of Rows 2
Packaging Type Carton
Panel Mount No
Pitch - Mating Interface 2.54mm
Polarized to Mating Part Yes
Ports 1
Stackable No
Temperature Range - Operating -40°C to +100°C

Electrical
Current - Maximum per Contact 10.2A

Material Info

Reference - Drawing Numbers
[Application Specification](#) AS-34691-100
[Product Specification](#) PS-31408-100
[Sales Drawing](#) SD-31408-900

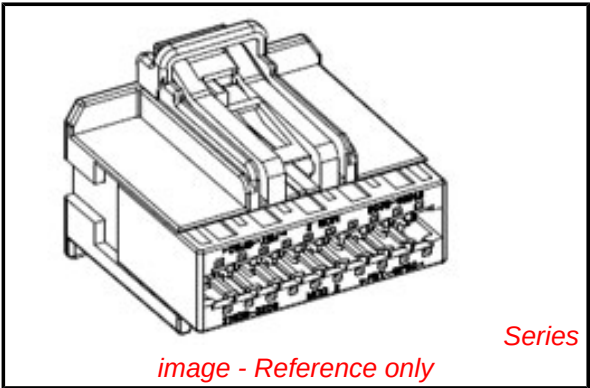

EU RoHS
ELV and RoHS Compliant
REACH SVHC
Not Reviewed
Low-Halogen Status
Low-Halogen

China RoHS

Need more information on product environmental compliance?

Email productcompliance@molex.com
For a multiple part number RoHS Certificate of Compliance, [click here](#)

Please visit the [Contact Us](#) section for any non-product compliance questions.

Search Parts in this Series
[31408Series](#)

Mates With
[34691](#) Stac64 Right Angle Assembly. [34690](#) Stac64 Vertical Assembly

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Molex:

31408-1161