

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0334670006

Status:


Active

Overview:

MX64 Sealed Connectors

Description:

2.54mm Pitch MX64 Terminal, Gold (Au) Plating, 18-20 AWG, Left Reel Payoff, Also used with MX123 Female Receptacle Housing

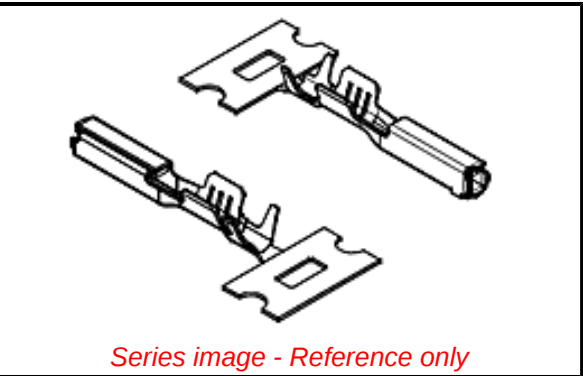

- Documents:
- Drawing (PDF)

Product Specification PS-33468-001-001 (PDF)

Application Specification AS-33468-001-001 (PDF)

Packaging Specification 313025040-000 (PDF)

Packaging Specification PK-30907-759-001 (PDF)

Packaging Specification PK-31300-516-001 (PDF)

Packaging Specification PK-31302-480-001 (PDF)

Datasheet (PDF)

RoHS Certificate of Compliance (PDF)

General	
Product Family	Crimp Terminals
Series	33467
Application	Automotive, Power, Wire-to-Board, Wire-to-Wire
Comments	Left Reel Payoff
Crimp Quality Equipment	Yes
Overview	MX64 Sealed Connectors
Product Name	MX123, MX64
UPC	756054763391
Physical	
Gender	Female
Material - Metal	Copper
Material - Plating Mating	Gold
Net Weight	0.225/g
Packaging Type	Reel
Plating min - Mating	0.762µm
Termination Interface: Style	Crimp or Compression
Wire Insulation Diameter	1.50-2.06mm
Wire Size AWG	18, 20
Wire Size mm²	N/A
Solder Process Data	
Lead-freeProcess Capability	N/A
Material Info	
Reference - Drawing Numbers	
Application Specification	AS-33468-001-001
Packaging Specification	313025040-000, PK-30907-759-001, PK-31300-516-001, PK-31302-480-001
Product Specification	PS-33468-001-001
Sales Drawing	SD-33468-001-001

EU ELV

Compliant

EU RoHS

Compliant

China RoHS

Compliant

REACH SVHC

Not Contained Per - D(2021)4569-DC (8 July 2021)

Halogen-Free

Status

Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

Green Image

ELV

Compliant

RoHS Phthalates

Not Contained

Search Parts in this Series

33467 Series

Use With

MX64 Sealed Single Row Crimp Housing 31403 , MX123 Female Receptacle Housing 34566 , 34576

Application Tooling | FAQ

Tooling specifications and manuals are found by selecting the products below. Crimp Height Specifications are then contained in the Application Tooling Specification document.

Global

Description	Product #
PremiumGrade Hand Crimp Tool for 2.54mm MX64 Terminals, 18-22 AWG	638114200
Extraction Tool for SPOX, MX64, Ditto, MX150CE, Milli-Grid Terminals	638131400

This document was generated on 12/28/2021

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Molex:

[33467-0006 \(Cut Strip\)](#) [33467-0006 \(Mouser Reel\)](#)