

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0334670022

Status:


Active

Overview:

MX64 Sealed Connectors

Description:

2.54mm Pitch MX64 Terminal, Gold (Au) Plating, 0.35mm2 Wire, Right Reel Payoff, Also used with MX123 Female Receptacle Housing

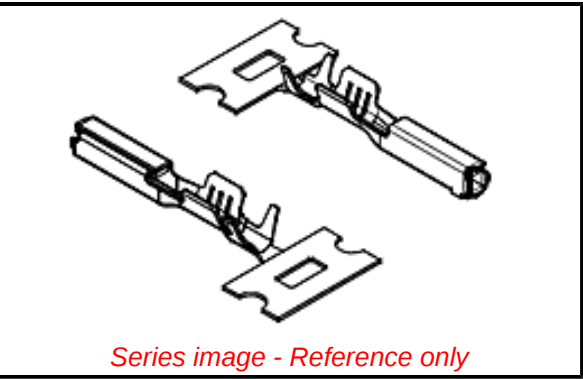

Series image - Reference only

Documents:

Drawing (PDF)

Product Specification PS-33468-001-001 (PDF)

Application Specification AS-33468-002-001 (PDF)

Packaging Specification PK-30907-759-001 (PDF)

Packaging Specification PK-31300-516-001 (PDF)

Packaging Specification PK-31302-480-001 (PDF)

Datasheet (PDF)

RoHS Certificate of Compliance (PDF)

General	
Product Family	Crimp Terminals
Series	33467
Application	Automotive, Power, Wire-to-Board, Wire-to-Wire
Comments	Right Reel Payoff For automatic and semi-automatic crimping, use Left Reel Payoff terminals. See Sales Drawing for Left Reel Payoff Part Numbers.
Crimp Quality Equipment	Yes
Overview	MX64 Sealed Connectors
Product Name	MX123, MX64
UPC	884982720626
Physical	
Gender	Female
Material - Metal	Copper
Material - Plating Mating	Gold
Net Weight	0.213/g
Packaging Type	Reel
Plating min - Mating	0.762µm
Termination Interface: Style	Crimp or Compression
Wire Insulation Diameter	1.50-2.06mm
Wire Size AWG	N/A
Wire Size mm²	0.35
Material Info	
Reference - Drawing Numbers	
Application Specification	AS-33468-002-001
Packaging Specification	PK-30907-759-001, PK-31300-516-001, PK-31302-480-001
Product Specification	PS-33468-001-001
Sales Drawing	SD-33468-002-001

EU ELV	
Compliant	
EU RoHS	China RoHS
Compliant	
REACH SVHC	
Not Contained Per - D(2021)4569-DC (8 July 2021)	
Halogen-Free	
Status	
Not Relevant	
For more information, please visit Contact US	
China ROHS	Not Relevant
ELV	Compliant
RoHS Phthalates	Not Contained

Search Parts in this Series

33467 Series

Use With

MX64 Sealed Single Row Crimp Housing 31403 , MX123 Female Receptacle Housing 34566 , 34576

Application Tooling FAQ	
Tooling specifications and manuals are found by selecting the products below. Crimp Height Specifications are then contained in the Application Tooling Specification document.	
Global	
Description	Product #
Hand Tool for MX64 ISO Terminal	638258400

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Molex:

33467-0022