

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0348268125

Status:


Active

Overview:

Mini50 Connection Systems

Description:

Mini50 Unsealed Right-Angle Header, Dual Row, 12 Circuit, Polarization Option B, 2.80mm Pin Length, Gray, Tape and Reel

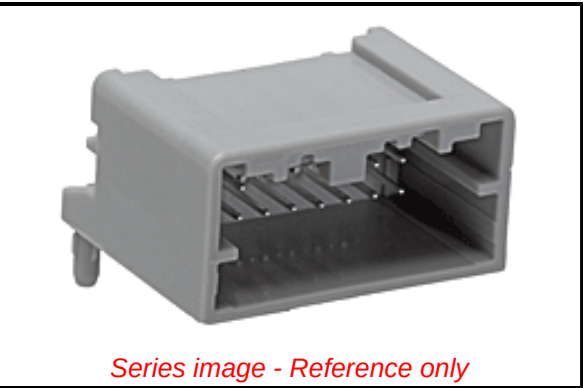

Series image - Reference only

Documents:

- Drawing (PDF)

3D Model (PDF)

3D Model

Product Specification PS-34791-020-001 (PDF)

Application Specification AS-34791-020-001 (PDF)

Application Specification AS-34791-020-CH-001 (PDF)
- Packaging Specification PK-31301-786-001 (PDF)

Packaging Specification PK-47799-0001-001 (PDF)

Test Summary 347910020-TS-000 (PDF)

Datasheet (PDF)

RoHS Certificate of Compliance (PDF)

General

Product Family	PCB Headers
Series	34826
Application	Automotive, Power, Signal, Wire-to-Board
Overview	Mini50 Connection Systems
Product Name	Mini50
UPC	191128064125

Physical

Breakaway	No
Circuits (Loaded)	12
Circuits (maximum)	12
Color - Resin	Gray
Durability (mating cycles max)	10
First Mate / Last Break	No
Glow-Wire Capable	No
Guide to Mating Part	No
Keying to Mating Part	Yes
Lock to Mating Part	Yes
Material - Metal	Brass
Material - Plating Mating	Tin
Material - Plating Termination	Tin
Material - Resin	High Temperature Thermoplastic
Net Weight	2.414/g
Number of Rows	2
Orientation	Right Angle
PC Tail Length	2.80mm
PCB Locator	Yes
Packaging Type	Embossed Tape on Reel
Pitch - Mating Interface	2.00mm
Polarized to Mating Part	Yes
Polarized to PCB	Yes
Temperature Range - Operating	-40° to +105°C
Termination Interface: Style	Through Hole

Electrical

Current - Maximum per Contact	4.0A (for reference only)
Voltage - Maximum	14V (typical operating)

Material Info

Reference - Drawing Numbers

Application Specification	AS-34791-020-001, AS-34791-020-CH-001
---------------------------	---------------------------------------

EU ELV

Compliant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -
D(2020)9139-DC (19
Jan 2021)

Halogen-Free

Status

Low-Halogen

For more information, please visit [Contact US](#)

China ROHS	Green Image
ELV	Compliant
RoHS Phthalates	Not Contained

Search Parts in this Series

34826 Series

Mates With

Mini50 Unsealed Dual Row Receptacle
34824

Packaging Specification
Product Specification
Sales Drawing
Test Summary

PK-31301-786-001, PK-47799-0001-001
PS-34791-020-001
SD-34826-001-001
347910020-TS-000

This document was generated on 09/02/2021

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[34826-8125](#)