

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0348408430

Status:


Active

Overview:

MX150 Sealed and Unsealed Connector System

Description:

MX150 Sealed Male Connector, Bulkhead Twist-Lock, Dual Row, 16 Circuits, Polarization C, Dark Gray

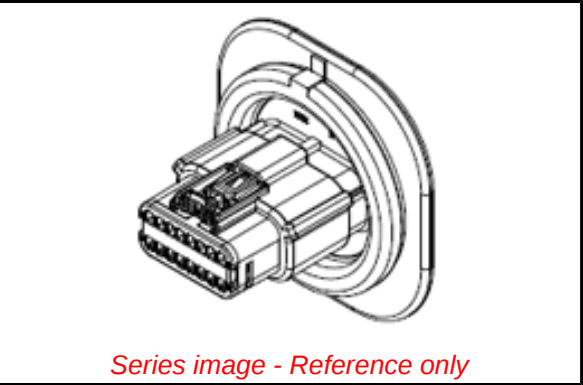

Documents:

3D Model

Drawing (PDF)

Drawing (PDF)

Product Specification PS-34840-0001-001 (PDF)

Application Specification AS-34840-001-001 (PDF)

Packaging Specification PK-31301-615-001 (PDF)

RoHS Certificate of Compliance (PDF)

General	
Product Family	Crimp Housings
Series	34840
Application	Power, Wire-to-Wire
Overview	MX150 Sealed and Unsealed Connector System
Product Name	MX150
UPC	191128256780
Physical	
Circuits (maximum)	16
Color - Resin	Gray (Dark), Natural
Gender	Plug
Glow-Wire Capable	No
Keying to Mating Part	Yes
Lock to Mating Part	Yes
Material - Resin	Modified Polystyrene Alloy
Number of Rows	2
Packaging Type	Bag
Panel Mount	Yes
Pitch - Mating Interface	3.50mm
Polarized to Mating Part	Yes
Stackable	No
Temperature Range - Operating	-40°C to +125°C
Material Info	
Reference - Drawing Numbers	
Application Specification	AS-34840-001-001
Packaging Specification	PK-31301-615-001
Product Specification	PS-34840-0001-001
Sales Drawing	SD-34840-001-001

EU ELV

Not Reviewed

EU RoHS

China RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

Need more information on product environmental compliance?

Email productcompliance@molex.com

Please visit the [Contact Us](#) section for any non-product compliance questions.

China ROHS

Not Reviewed

ELV

Not Reviewed

RoHS Phthalates

Not Reviewed

Search Parts in this Series

34840 Series

Mates With

33472 MX150 Sealed Connector

Use With

33000 MX150 Male Terminal

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[34840-8430](#) [34840-8420](#) [34840-4420](#) [34840-6430](#) [34840-6410](#) [34840-3420](#) [34840-6440](#) [34840-3440](#) [34840-3430](#) [34840-4440](#) [34840-8440](#) [34840-4430](#) [34840-3410](#) [34840-4410](#) [34840-8410](#) [34840-6420](#)