

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0349617342

Status:


Active

Overview:

Mini50 Connection Systems

Description:

Mini50 Unsealed Right-Angle Hybrid Header, 3 Rows, 34 Circuits, Polarization Option C, Dark Gray, Tube

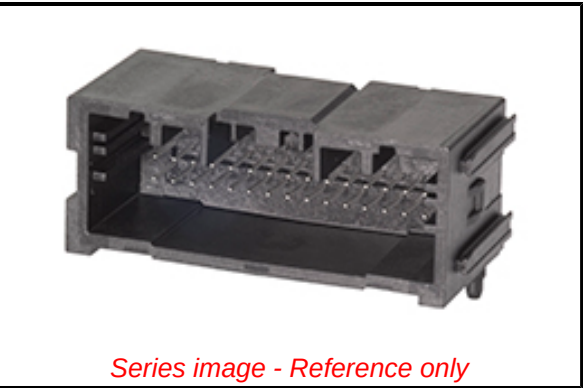

Documents:

- [3D Model](#)
[Drawing \(PDF\)](#)
[3D Model \(PDF\)](#)
[Product Specification PS-34959-001-001 \(PDF\)](#)
[Application Specification 349590001-AS-CH-000 \(PDF\)](#)
- [Application Specification AS-34959-001-001 \(PDF\)](#)
[Packaging Specification PK-31301-688-001 \(PDF\)](#)
[Datasheet \(PDF\)](#)
[RoHS Certificate of Compliance \(PDF\)](#)

General

Product Family	PCB Headers
Series	34961
Application	Automotive, Power, Signal, Wire-to-Board
Comments	30 x 0.50mm blades = 4.0A; 4 x 1.20mm blades = 16.0A
Overview	Mini50 Connection Systems
Product Name	Mini50
UPC	887191921532

Physical

Breakaway	No
Circuits (Loaded)	34
Circuits (maximum)	34
Color - Resin	Gray (Dark)
Durability (mating cycles max)	10
First Mate / Last Break	No
Glow-Wire Capable	No
Guide to Mating Part	No
Keying to Mating Part	Yes
Lock to Mating Part	Yes
Material - Metal	Brass
Material - Plating Mating	Tin
Material - Plating Termination	Tin
Material - Resin	SPS
Net Weight	6.480/g
Number of Rows	3
Orientation	Right Angle
PC Tail Length	2.75mm
PCB Locator	Yes
PCB Retention	None
Packaging Type	Tube
Pitch - Mating Interface	2.00mm
Polarized to Mating Part	Yes
Polarized to PCB	Yes
Stackable	Yes
Surface Mount Compatible (SMC)	No
Temperature Range - Operating	-40° to +105°C
Termination Interface: Style	Through Hole

Electrical

Current - Maximum per Contact	16.0A, 4.0A
Voltage - Maximum	500V DC

EU ELV

Compliant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -
D(2021)4569-DC (8
July 2021)

Halogen-Free

Status

Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

China RoHS

Green Image

Compliant

Not Contained

Search Parts in this Series

34961 Series

Mates With

Mini50 Unsealed Receptacle [349590342](#) ,
[349590349](#)

Material Info

Reference - Drawing Numbers

Application Specification	349590001-AS-CH-000, AS-34959-001-001
Packaging Specification	PK-31301-688-001
Product Specification	PS-34959-001-001
Sales Drawing	SD-34961-030-001

This document was generated on 10/04/2021

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[34961-7342](#)