

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0350230006

Status:

Active

Overview:

Board-in Connectors


Description:

2.00mm Pitch, Board-In Crimp Housing, Right-Angle, 6 Circuits, Natural

Documents:	
3D Model	Product Specification PS-35023-001-001 (PDF)
Drawing (PDF)	Packaging Specification PK-35023-001-001 (PDF)
3D Model (PDF)	RoHS Certificate of Compliance (PDF)

Agency Certification	
CSA	LR19980
UL	E29179
General	
Product Family	Crimp Housings
Series	35023
Application	Signal, Wire-to-Board
Overview	Board-in Connectors
Product Name	Board-in
UPC	800754255271
Physical	
Circuits (maximum)	6
Color - Resin	Natural
Flammability	94V-0
Gender	N/A
Glow-Wire Capable	No
Material - Resin	Nylon
Net Weight	0.102/g
Number of Rows	1
Packaging Type	Bag
Panel Mount	No
Pitch - Mating Interface	2.00mm
Stackable	No
Temperature Range - Operating	-40° to +105°C
Solder Process Data	
Lead-freeProcess Capability	N/A

Material Info	
Reference - Drawing Numbers	
Packaging Specification	PK-35023-001-001
Product Specification	PS-35023-001-001
Sales Drawing	SD-35023-001-001

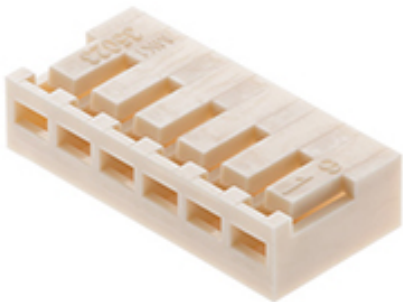

Series image - Reference only

EU ELV	
Not Relevant	
EU RoHS	China RoHS
Compliant	
REACH SVHC	
Not Contained Per - D(2021)4569-DC (8 July 2021)	
Halogen-Free	
Status	
Low-Halogen	
For more information, please visit Contact US	
China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

35023 Series

Use With

Straight Terminal [350449102](#) , [350449260](#)

Right Angle Terminal [350211201](#) , [350211301](#) , [350211360](#)

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[35023-0006](#)