

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [35189-0200](#)
Status: **Active**
Description: 4.75mm Tab, MP-Lock™ Housing, 2 Circuits, 6.00mm Pitch, UL94V-2, Natural

Documents:
[3D Model](#) [Packaging Specification PK-35189-002 \(PDF\)](#)
[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

CSA LR95446
UL E29179

General

Product Family Crimp Housings
Series [35189](#)
Application Power
Product Name MP-Lock™
UPC 800754376167

Physical

Breakaway No
Circuits (maximum) 2
Flammability 94V-2
Gender Female
Glow-Wire Compliant No
Keying to Mating Part None
Lock to Mating Part None
Net Weight 1.150/g
Number of Rows 2
Packaging Type Bag
Panel Mount No
Pitch - Mating Interface 6.00mm
Pitch - Termination Interface 6.00mm
Polarized to Mating Part Yes
Stackable No
Temperature Range - Operating -40°C to +105°C


Electrical

Current - Maximum per Contact 12A

Material Info

Reference - Drawing Numbers

Packaging Specification PK-35189-002
Product Specification RPS-35068-001
Sales Drawing SD-35189-0200

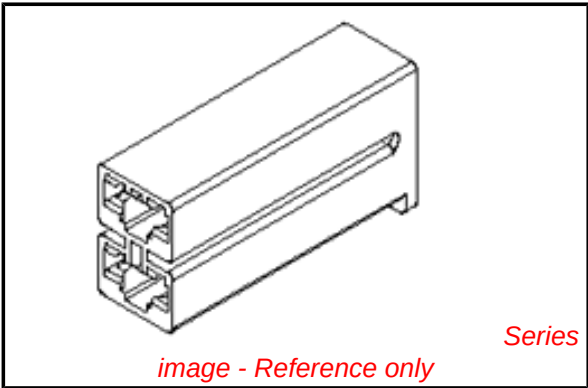

EU RoHS

**ELV and RoHS
Compliant**
REACH SVHC
Contains SVHC: No
Low-Halogen Status
Low-Halogen

China RoHS



**Need more information on product
environmental compliance?**

Email productcompliance@molex.com
For a multiple part number RoHS Certificate of
Compliance, [click here](#)

Please visit the [Contact Us](#) section for any
non-product compliance questions.

Search Parts in this Series

[35189Series](#)

Mates With

Appliance Timer|Temperature Switch|
Micro Switch|Appliance Motor|Appliance
Magnetron|Appliance Capacitor|Appliance
Transformer|Appliance Heater

Use With

[35068](#) MP-Lock™ Quick Disconnect

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Molex:

35189-0200