

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0352840610

Status:

Active

Description:

2.28mm Tab Wire-to-Wire Uniconn Housing, Female, 6 Circuits

Documents:

3D Model

Packaging Specification PK-35284-001 (PDF)

Drawing (PDF)

RoHS Certificate of Compliance (PDF)

Product Specification PS-35282-001 (PDF)

General

Product Family

Crimp Housings

Series

35284

Application

Power, Wire-to-Wire

Product Name

Uniconn

Physical

Circuits (maximum)

6

Color - Resin

Black, Natural

Gender

Female

Glow-Wire Compliant

No

Material - Resin

Polyester

Number of Rows

2

Packaging Type

Bag

Panel Mount

No

Pitch - Mating Interface

3.81mm

Temperature Range - Operating

-40°C to +80°C

Material Info

Reference - Drawing Numbers

Packaging Specification


PK-35284-001

Product Specification

PS-35282-001

Sales Drawing

SD-35284-001, SD-35284-0610

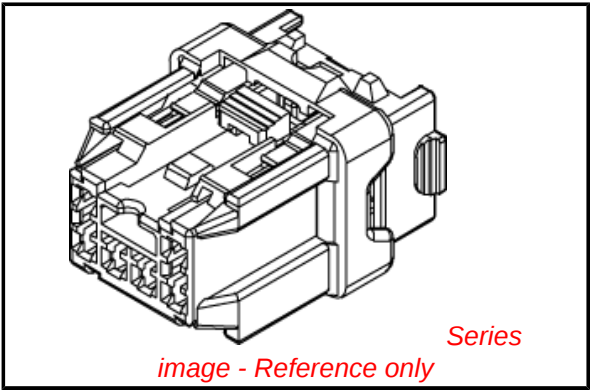

EU RoHS

ELV and RoHS

Compliant

REACH SVHC

Contains SVHC: No

Low-Halogen Status

Low-Halogen

China RoHS



Need more information on product environmental compliance?

Email productcompliance@molex.com
For a multiple part number RoHS Certificate of Compliance, [click here](#)

Please visit the [Contact Us](#) section for any non-product compliance questions.

Search Parts in this Series

35284Series

Mates With

35282

Use With

35420 , 35421

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[35284-0610](#)