

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0354301900](#)
Status: **Active**
Description: 6.00mm Tab Wire-to-Wire Terminal, Female, Two-Piece Type, Wire Range AVS

Documents:

[Drawing \(PDF\)](#)
[Product Specification PS-35270-001-001 \(PDF\)](#)
[Product Specification PS-35385-001-001 \(PDF\)](#)
[Packaging Specification PK-35430-001-001 \(PDF\)](#)
[RoHS Certificate of Compliance \(PDF\)](#)

General

Product Family Crimp Terminals
Series [35430](#)
Application Power, Wire-to-Wire
Crimp Quality Equipment Yes
Product Name N/A
UPC 756054160459

Physical

Gender Female
Material - Metal Copper-Nickel-Tin, High Copper Alloy
Material - Plating Mating Tin
Material - Plating Termination Tin
Net Weight 1.120/g
Packaging Type Reel
Plating min - Mating 0.813µm
Plating min - Termination 0.813µm
Termination Interface: Style Crimp or Compression
Wire Insulation Diameter 3.10-4.20mm
Wire Size AWG 12, 14
Wire Size mm² N/A

Electrical

Current - Maximum per Contact 30.0A


Solder Process Data

Lead-freeProcess Capability N/A

Material Info

Reference - Drawing Numbers

Crimp Specification CS-35430-001-001
Packaging Specification PK-35430-001-001
Product Specification PS-35270-001-001, PS-35385-001-001
Sales Drawing SD-35430-001-001

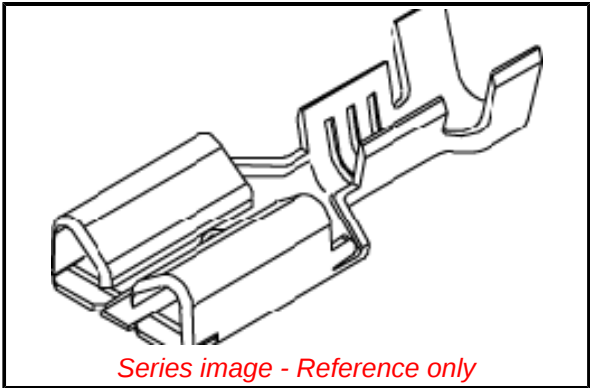

EU ELV

Compliant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -
D(2020)9139-DC (19
Jan 2021)

Halogen-Free

Status

Low-Halogen

For more information, please visit [Contact US](#)

China RoHS

China ROHS	Not Relevant
ELV	Compliant
RoHS Phthalates	Not Contained

Search Parts in this Series

[35430](#) Series

Mates With

[35725](#) Terminal

Use With

[35270](#) Housing

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[35430-1900](#)