

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0355721000](#)
Status: **Active**
Description: 2.50mm Pitch Wire-to-Wire and Wire-to-Board Housing, Positive Lock, PBT, 10 Circuits, Natural

Documents:

[3D Model](#) [Packaging Specification PK-35572-001-001 \(PDF\)](#)
[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)
[Product Specification PS-35572-001 \(PDF\)](#)

Agency Certification

UL E29179

General

Product Family Crimp Housings
Series [35572](#)
Application Signal, Wire-to-Board, Wire-to-Wire
Product Name N/A
UPC 800755993301


Physical

Breakaway No
Circuits (maximum) 10
Color - Resin Natural
Flammability 94V-0
Gender Receptacle
Glow-Wire Capable No
Keying to Mating Part None
Lock to Mating Part Yes
Material - Resin PBT
Net Weight 0.847/g
Number of Rows 1
Packaging Type Bag
Panel Mount No
Pitch - Mating Interface 2.50mm
Pitch - Termination Interface 2.50mm
Temperature Range - Operating -40° to +105°C

Material Info

Reference - Drawing Numbers

Packaging Specification PK-35572-001-001
Product Specification PS-35572-001
Sales Drawing SD-35572-001

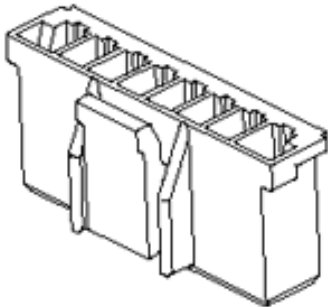

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

China RoHS

REACH SVHC

Not Contained Per -
ED/61/2018 (27 June
2018)

Halogen-Free

Status

Not Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

Green Image

ELV

Not Relevant

RoHS Phthalates

Not Contained

Search Parts in this Series

[35572](#) Series

Mates With

[35312](#) Vertical Shrouded Header, [35184](#)
Plug Housing

Use With

[57915](#) Wire-to-Board Terminal

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Molex:

[35572-1000](#)