

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0357180900

Status:


Active

Overview:

Standard Quick-Disconnect Terminals

Description:

4.75mm Tab Slip-On Terminal, Female, 0.51mm Tab Thickness, Wire Range 16-20 AWG (1.31-0.52mm²), Unplated

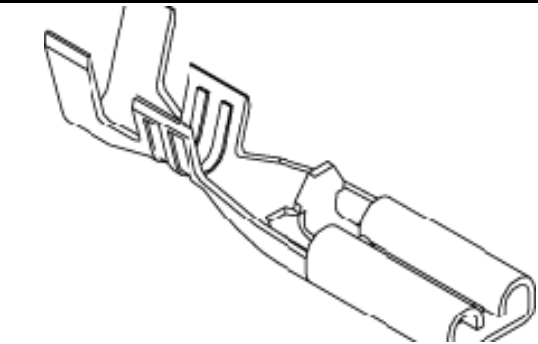

Series image - Reference only

Documents:

Drawing (PDF)

Product Specification PS-35703-001-001 (PDF)

Packaging Specification PK-35718-001-001 (PDF)

RoHS Certificate of Compliance (PDF)

Agency Certification	
UL	E92853
General	
Product Family	Quick Disconnects
Series	35718
Crimp Quality Equipment	Yes
Insulated	No
Overview	Standard Quick-Disconnect Terminals
Product Name	Slip-On
Type	Quick Disconnect
UPC	756054254752
Physical	
Barrel Type	Open
Gender	Female
Glow-Wire Compliant	No
Insulation	None
Lock to Mating Part	Yes
Material - Metal	Brass
Material - Plating Mating	Tin
Material - Plating Termination	Tin
Net Weight	0.400/g
Orientation	Straight
Packaging Type	Reel
Plating min - Mating	1.016µm
Plating min - Termination	1.016µm
Polarized to Mating Part	No
Tab Thickness	0.51mm
Tab Width	4.75mm
Temperature Range - Operating	-40°C to +105°C
Termination Interface: Style	Crimp or Compression
Wire Insulation Diameter	3.50mm max.
Wire Size AWG	16, 18, 20
Wire Size mm²	0.50-1.30
Electrical	
Voltage - Maximum	250V
Material Info	
Reference - Drawing Numbers	
Packaging Specification	PK-35718-001-001
Product Specification	PS-35703-001-001
Sales Drawing	SD-35718-09*0

EU ELV

Not Relevant

EU RoHS

Compliant

China RoHS

REACH SVHC

Not Contained Per -
ED/30/2017 (7 July
2017)

Halogen-Free

Status

Low-Halogen

Need more information on product
environmental compliance?

Email productcompliance@molex.com
Please visit the [Contact Us](#) section for any
non-product compliance questions.

China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

35718 Series

Use With

4.75mm Tab

This document was generated on 07/31/2017

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[35718-0900](#)